


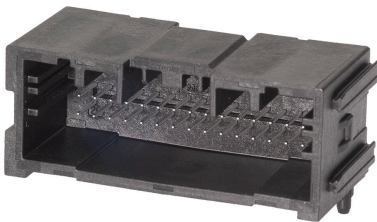

**Part Number :** [349610386](#)  
**Product Description :** Mini50 Unsealed Right-Angle Header, UL 94 HB, 38 Circuits, Polarization A, Black, Tray  
**Series Number :** [34961](#)  
**Status :** Active  
**Product Category :** PCB Headers and Receptacles



## Documents & Resources

**Drawings**  
[349610386\\_sd.pdf](#)

**3D Models and Design Files**  
[349610386\\_stp.zip](#)

**Specifications**  
[TS-34961-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	Not Relevant
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	PCB Headers and Receptacles
Series	34961
Description	Mini50 Unsealed Right-Angle Header, UL 94 HB, 38 Circuits, Polarization A, Black, Tray
Application	Automotive, Power, Signal, Wire-to-Board
Comments	38 x 0.50mm blades = 4.0A
Component Type	PCB Header
Product Name	Mini50
UPC	195842848061

#### Electrical

Current - Maximum per Contact	4.0A
Voltage - Maximum	500V DC

#### Physical

Breakaway	No
Circuits (Loaded)	38
Circuits (maximum)	38
Color - Resin	Black
Durability (mating cycles max)	10
First Mate / Last Break	No
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Metal	Brass
Material - Plating Mating	Tin

Material - Plating Termination	Tin
Material - Resin	SPS
Net Weight	6.300/g
Number of Rows	3
Orientation	Right Angle
Packaging Type	Tray
PC Tail Length	2.75mm
PCB Locator	Yes
PCB Retention	None
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Termination Interface Style	Through Hole

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Mini50 Unsealed Receptacle, 3 Rows, without CPA, 38 Circuits, Polarization Option A, Black	<u>349590390</u>
Mini50 Unsealed Receptacle, 3 Rows, with CPA, 38 Circuits, Polarization Option A, Black	<u>349590383</u>

---

This document was generated on Mar 04, 2025