

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0887538502

Status:

Active

Overview:

usb

Description:


USB On-The-Go (OTG) Shielded I/O Cable Assembly, Mini A-to-Mini B, USB 2.0, 1.80m Length, Black

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	88740
Connector to Connector	USB Mini-A-to-Mini-B
Overview	usb
Product Name	USB
Physical	
Cable Length	1.80m
Circuits (Loaded)	5
Color - Resin	Black
Gender	Male-Male
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	Polyester
Packaging Type	Bag
Pitch - Mating Interface	0.80mm
Plating min - Mating	0.762µm
Plating min - Termination	4.064µm
Single Ended	No
Termination Interface: Style	Through Hole
Wire Insulation Diameter	N/A
Wire Size AWG	28
Wire/Cable Type	Round
Electrical	
Current - Maximum per Contact	1A
Shielded	Yes
Voltage - Maximum	30V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-887538200

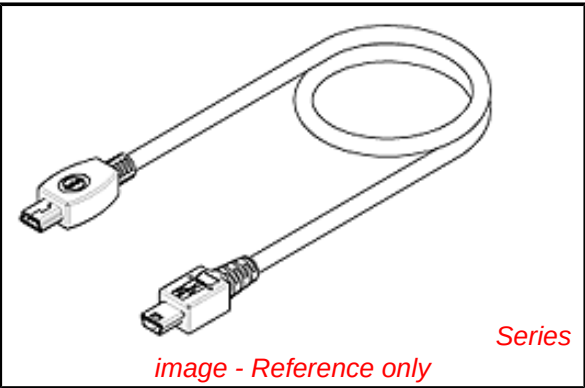

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

88740Series

Mates With

USB On-The-Go (OTG) Mini-B Receptacle

54819 , 51387 , 48242Link:500075. 56579

USB On-The-Go (OTG) Mini-AB Receptacle

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION