

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1210120107

Status:

Active

Overview:

mPm DIN Valve Connectors

Description:

mPm DIN Base, Form B-11mm, B29 Base, 3 Pole Plus Ground Terminal, 250V AC/300V DC, Black, Nitrile Gasket with Screws

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Field Attachable / Accessories

Series

121012

Form

B - 11mm

IP Rating

IP65, IP67

Material - Contact

Brass

Overview

mPm DIN Valve Connectors

Product Name

mPm

Type

Field Attachable Connector

UPC

883906248758

Physical

Cable Diameter

N/A

Coupling Type

N/A

Diagnostics / LEDs

No

Diagnostics Port

No

Gender

N/A

Keyway

None

Material - Connector Body

Polypropylene

Material - Coupling Nut

N/A

Material - Plating Mating

Tin

Net Weight

7.603/g

Orientation

Straight

Pitch - Mating Interface

11.00mm

Poles

3

Temperature Range - Operating

-40°C to +90°C

Wire Size AWG

N/A

Electrical

Current - Maximum per Contact

10.0A


Voltage - Maximum

250V AC / 300V DC

Material Info

Engineering Number

B293000N2

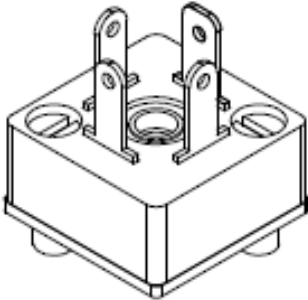

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free Status

Low-Halogen

For more information, please visit Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

121012 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION