


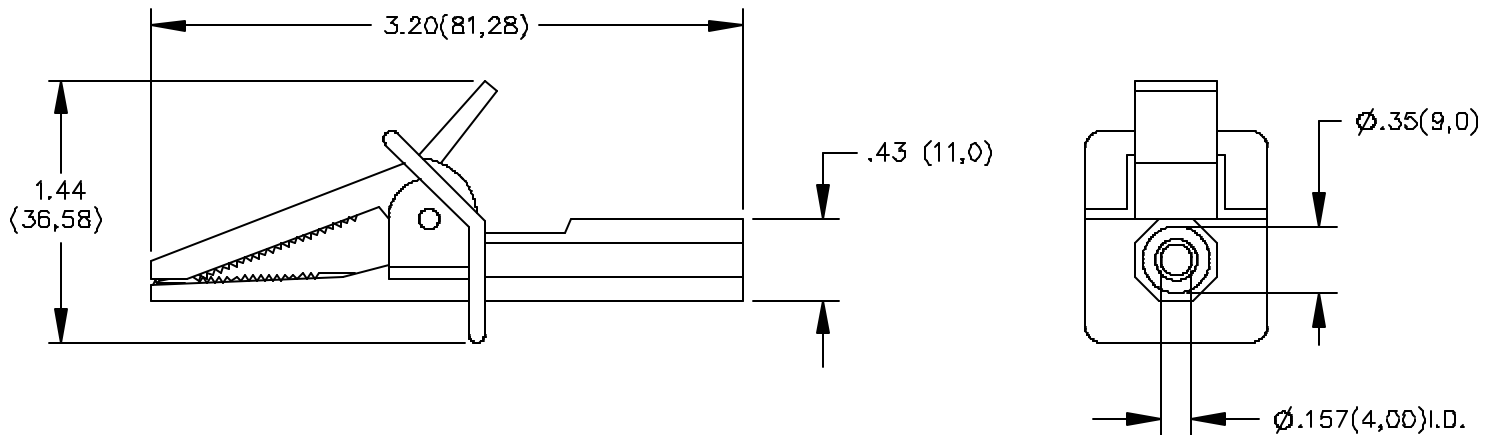

FEATURES:

- Extra large jaw opening (1") for use in industrial and automotive applications
- Conforms to IEC 1010-2-031
- Mates to Banana Plug Test Leads; Example Pomona Model 5908A

MATERIALS:

Body: Steel, nickel plated

Insulation: Thermoplastic, torsion spring – music wire

Color: One Black, one Red

RATINGS:

Operating Voltage: Category III, 600 VRMS

Current: 10 Amperes

ORDERING INFORMATION: Model 5914

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA