

All TH/.025 Connector System, Recpt and Tab (17)

Product Compliance

For compliance documentation, visit the product page on TE.com>

 
EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 1747331-1
HEADER ASSEMBLY



TE Part # CAT-T319-CH8172
TH/.025 CONNECTOR SYSTEM,
HOUSING



TE Part # 2836430-1
OCEAN_2.0_APPLICATOR-S-
070F086O-RSM



TE Part # 7-2836430-7
OCEAN_2.0_SPARE_PART_KIT-
070F086O



TE Part # CAT-M9194-CH8172
MULTILOCK, CONNECTOR HOUSING



TE Part # 2836430-2
OCEAN_2.0_APPLICATOR-S-
070F086O-RSA

Customers Also Bought



TE Part #DRB16-48SBE-L018
PLG, 48P, BLK, E, CAP, B




TE Part #DRB48-60-BT
BOOT, 48/60P, PLG/REC, ST, BLK




TE Part #DT06-12SA-EP08
PLG, 12P, BLK, N, SEAL RET, ENH KEY,
CAP, A



TE Part #DT04-12PA-BE03
REC, 12P, BLK, N, ENH KEY, CAP, A

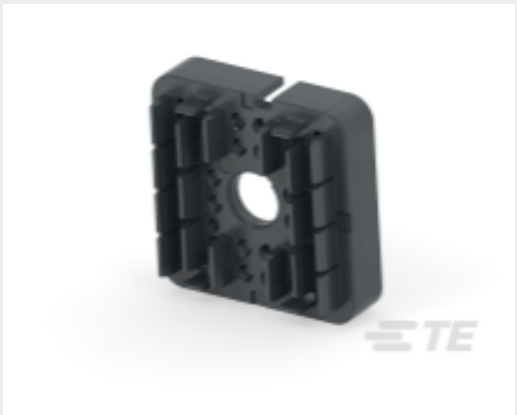

TE Part #WB-48PB
WEDGE LOCK, 48P, REC, BLK, DRB, B

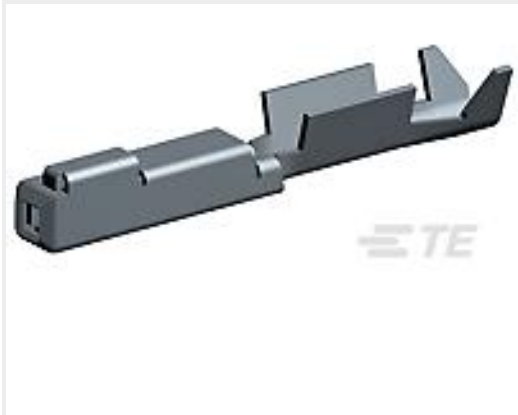

TE Part #1318329-1
.025 SEALED REC CONT



TE Part #1718350-1
MCON 1.2 CB TAB STC SN



TE Part #2292906-2
2POS, MCON 1.2, REC HSG ASSY, SLD,
COD B



TE Part #7G7920-6
SEAL PLUG, SIZE 4, BLU



TE Part #7G7918-12
SEAL PLUG, SIZE 12, YEL

Documents



Product Drawings

.040 SEALED REC CONT

English

CAD Files

Customer View Model

ENG_CVM_CVM_1318332-1_G.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1318332-1_G.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1318332-1_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Crimping CLEAN BODY 025/040 Receptacle Contact

English

Application Specification

English

Application Specification

Japanese

Crimping CLEAN BODY 025/040 Receptacle Contact

Japanese

Instruction Sheets

Instruction Sheet (non U.S.)

Japanese

The Extraction Tool for 025/040 Clean Body Connector

Japanese

Instruction Sheet (non U.S.)

Japanese