

5

4

3

2



1

D

C

B


A

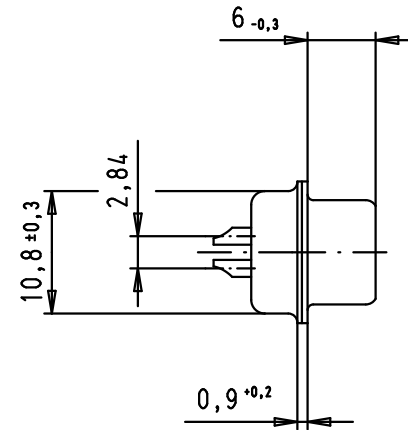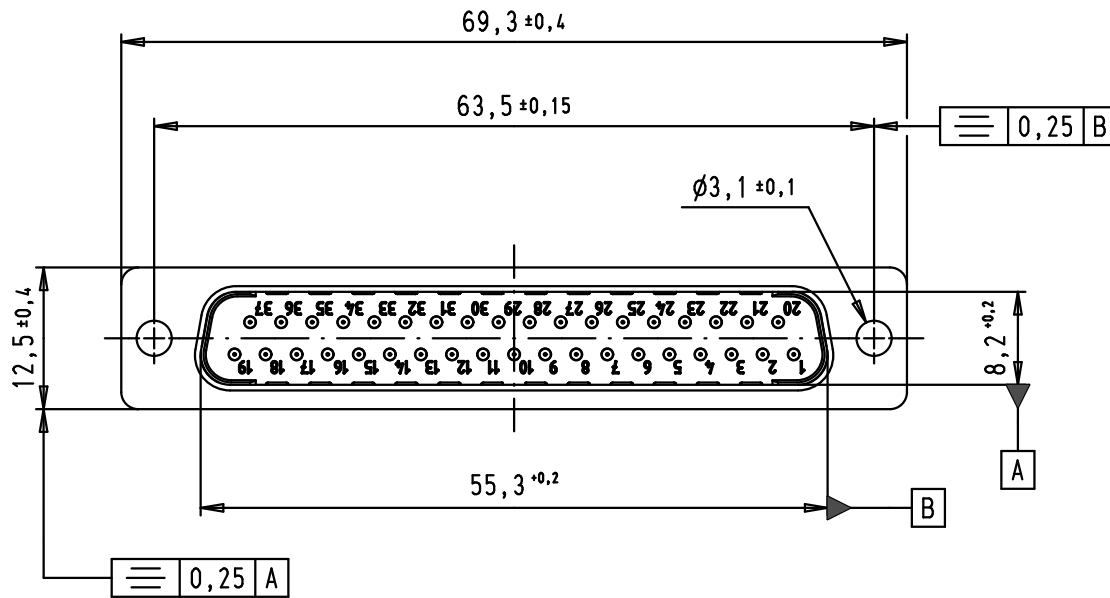


SPECIFICATIONS

Performance level	PL2
Filter type	C
Capacitance	47 pF±20%
Working voltage	100 V
Current rating	7,5 A
Insulation resistance	>1 GΩ

FREQUENCY (MHz)	ATTENUATION (dB)
5	-
10	-
50	-
100	-
500	30
1000	35

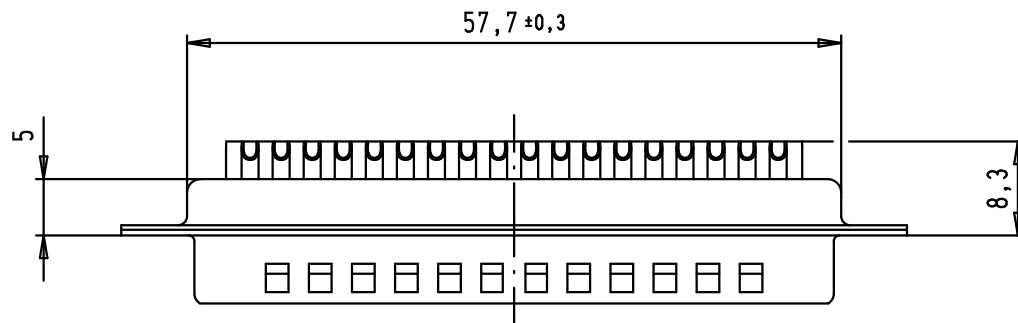

Solder buckets for AWG 20

 Mod.	Dat.	Name	Detail.	Dat.	Name	 All Dim. in mm Orig. Size DIN A 4	D-Sub, male, straight, 37 poles, turned solder buckets	Maßstab/ Scale 1,5:1
36283	12/01/12	SD	Insp.	08/07/02	CV			
35300	01/12/08	PK	Stand.	12/01/12	JB			
33800	21/08/06	PK						
31058	08/07/02	CV						

HARTING EURL
F-95972 Paris



TB 09 64 421 7210

Sub.

Blatt/ Page
1 / 1