


S3F8S6BXZZ-C0CB

- Package - Pellet (Die)
- I/O - 54
- Interrupts - 30
- Timers - BT, WDT, WT, (3) 8-Bit, (2) 16-Bit
- Speed (MHz) - 12
- Operating Voltage - 1.8V-5.5V
- Other Features - (2) UART, SIO, LVR, IVC, PGM, DAC, Voltage Booster & Regulator
- RAM (bytes) - 2098
- Program Memory - 64 KB Flash
- 10-Bit A/D - 8
- LCD Segment - 28/8

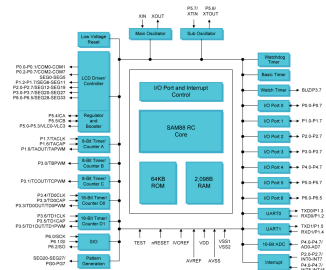

- Documentation

Select Distributor

Select Solution Partner

View Next MPN >>

Part Number	Package	Status	Part Number	Package	Status
S3F8S6BXZ-QT8B	64-pin QFP	Active	S3F8S6BXZ-AT9B	64-Pin SDIP	Active
S3F8S6BXZ-C0CB	Pellet (Die)	Active			

