


324486 Product Details

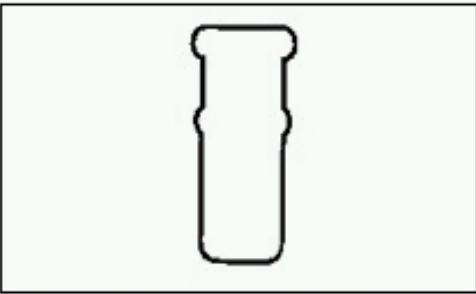

324486

TE Part Number: 324486

Active

Add to Part List

Splices - Closed Barrel

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Wire Caps for Unstripped Wire
- Not Sealed
- Body Style = PIDG
- Insulated
- Insulation Support

View all Features | Find Similar Products

Live Product Chat

Quick Links

- Check Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product
- Request Samples

NEW!

Documentation & Additional Information

Product Drawings:

- SPARE WIRE CAP,BLUE (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- Pre-Insulated Diamond Grip (PIDG) Terminals, Splices... (PDF, English)

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- Product Line Information

Related Products:

- Tooling

List all Documents

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Wire Caps for Unstripped Wire
- Sealed = No
- Body Style = PIDG
- Insulation = Yes
- Insulation Support = Insulation Support
- Insulation Diameter (mm [in]) = 3.05-3.68 [.120-.145]
- Material = Copper
- Finish = Tin
- Color = Blue

Industry Standards:

- Government/Industry Qualification = No
- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Packaging Related Features:

- Packaging Method = Loose Piece

Other:

- Brand = AMP