

samtec



(0,80mm) .0315"

QEM8 SERIES



QEM8-060-05.0-L-D-A

QEM8-040-05.0-S-D-A

EDGE RATE™ CONTACT GROUND PLANE

SPECIFICATIONS

For complete specifications and recommended PCB layouts see www.samtec.com?QEM8

Insulator Material:

Black LCP

Terminal Material:

Phosphor Bronze

Plating:

Au over 50μ" (1,27μm) Ni

Current Rating:

Testing Now!

Operating Temp Range:

Testing Now!

Voltage Rating:

Testing Now!

Max Cycles:

Testing Now!

RoHS Compliant:

Yes

Processing:

Lead-Free Solderable:

Yes

SMT Lead Coplanarity:

(0,10mm) .004" max

Board Mates:
QEF8



Edge wiping contacts for reduced broadside coupling

Integral metal plane for power or ground

Increased insertion depth and contact wipe

Footprint compatible with QTE Series

(0,80mm) .0315" pitch

Polarized

(1,40mm) .055" NOMINAL WIPE

MATED HEIGHT*	
QEM8 LEAD STYLE	QEF8 LEAD STYLE
-05.0	(10,00) .394


*Processing conditions will affect mated height.



- Edge Rate™ contacts
- Increased contact wipe

QEM8	NO. OF POSITIONS PER ROW	LEAD STYLE	PLATING OPTION	D	A	OTHER OPTION
		-05.0 = 5mm Body Height	-S = 30μ" (0,76μm) Gold on Signal Pins and Ground Plane, Matte Tin on tails -L = 10μ" (0,25μm) Gold on Signal Pins and Ground Plane, Matte Tin on tails			-K = (10,25mm) .404" DIA Polyimide Film Pick & Place Pad -TR = Tape & Reel Packaging

NO. OF POSITIONS	A
-020	(26,82) 1.056
-040	(46,82) 1.843
-060	(66,82) 2.631

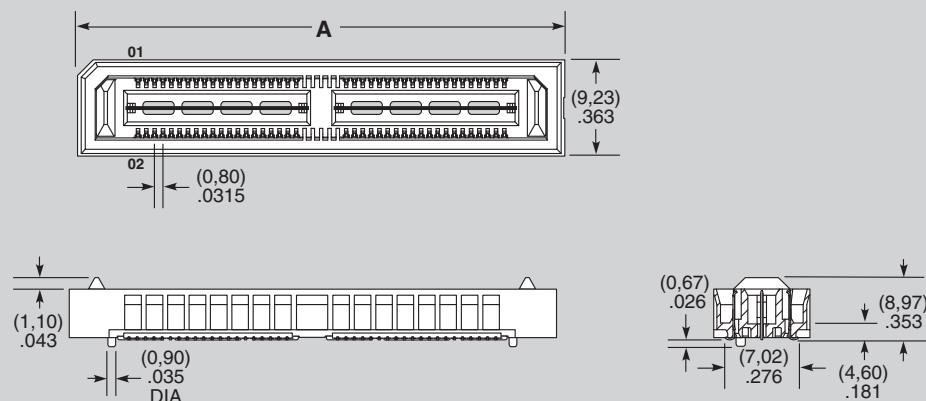

Note: Some lengths, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

WWW.SAMTEC.COM

SAMTEC USA • Tel: 1-800-SAMTEC-9 or 812-944-6733 SAMTEC SILICON VALLEY • Tel: 408-395-5900 SAMTEC SOUTHERN CALIFORNIA • Tel: 1-800-726-8329
 SAMTEC AMERICA LATINA COMERCIO EXTERIOR LTDA • Tel: (+55 31) 3786 3227 SAMTEC UNITED KINGDOM • Tel: 44 01236 739292 SAMTEC GERMANY • Tel: +49 (0) 89 / 89460-0
 SAMTEC FRANCE • Tel: 33 01 60 95 06 60 SAMTEC ITALY • Tel: 39 039 6890337 SAMTEC NORDIC/BALTIC • Tel: +46-84477280 SAMTEC BENELUX • Tel: 44 01236 739292
 SAMTEC ISRAEL • Tel: 972-3-7526600 SAMTEC INDIA • Tel: +91-80-3272 1612 SAMTEC ASIA PACIFIC • Tel: 65 6745-5955 SAMTEC JAPAN • Tel: 045-475-1385 SAMTEC CHINA • Tel: 86-21-61103766
 2735-6109 SAMTEC HONG KONG • Tel: 852-26904858 SAMTEC KOREA • Tel: 82-31-717-5685 SAMTEC ANZ • Tel: 613 9580 0683