

APSD00050432100M00

Search by :

Part Number

Characteristics

Cross reference



MP

Auto



Unshielded Type

Series Pdf



RoHSREACHCoC



Product detail

L(mm) ±	4.5±0.3
W(mm) ±	4.0±0.3
T(mm) ±	3.2±0.3
Inductance(uH)	10
Tolerance(±%)	20
Test Frequency	2.52 MHz,1 V
RDC(Ω)Max	0.182
Isat(A)	1.15
Operating Temperature	− 40℃~ 125℃(Including self - temperature rise)


Part Numbering

Dimensions

Packing

Recommended Pattern

Electrical Characteristics

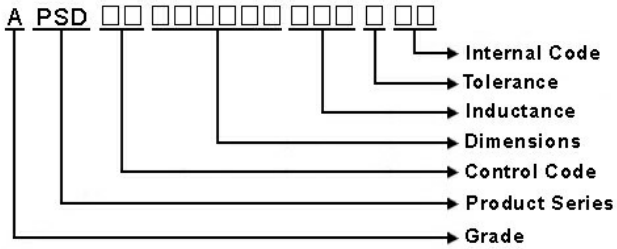

Products

Power Inductor
EMI-Common Mode Choke
EMI-Bead
RF-Signal Inductor
RF-Passives/Antennas
LAN Transformer
Resistor & Current Sensor

Applications

Automotive
Industrial
Server/DataCenter
Communication
Mobile and Tablet
Computer/Laptop
Consumer

Design Tools

Simulation Tool
Product Search Engine
E-Catalogue

About Us

Corporate Overview
Corporate Milestones
Core Technology
Certificates & Awards
Quality and Social Responsibility

Investor

Financial Information
Corporate governance
Stakeholder Contacts

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisín](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.