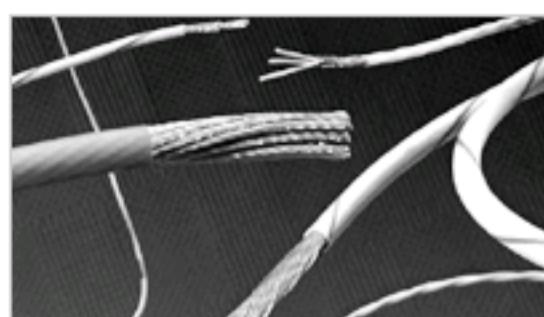


## CMC-0554-2-9 Product Details

 Active

### Power Cables

CMC-0554-2-9

**CMC-0554-2-9** 

TE Internal Number: 755767-000

 Share Print Email Feedback[Documents](#) [Features](#) [Compliance](#)**Please Note:**  
Use the Product Drawing for all design activity

#### Product Type Features

Insulation	Double Insulated
Color	White
Cable Type	Power

#### Electrical Characteristics

Number of Strands x AWG	665 Strands x 30 AWG
Voltage Rating (VAC)	600

#### Dimensions

Conductor Outer Diameter (mm [in])	8.38 [0.330]
------------------------------------	--------------

#### Body Features

Cable Jacket Material	Modified Fluoropolymer
Wire Size (AWG/CM)	2 AWG
Nominal Outside Diameter (mm [in])	10.72 [0.422]
Cable Jacket Color	White
Wire Diameter (mm [in])	10.72 [0.422]
Conductor Type	Nickel-Coated Copper
Insulation Material	XL-ETFE

#### Configuration Features

Number of Conductors	1
----------------------	---

#### Industry Standards

RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

#### Operation/Application

Application	High Temperature
-------------	------------------

#### Other

Brand	Raychem
-------	---------

#### Related Products

Not quite the product you're looking for?

[Find Similar Products](#)[View Part in Product Feature Selector](#)[Check for Tooling](#)

#### Corporate Information

[About TE](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)  
[Terms & Conditions](#)  
[Privacy Policy](#)  
[Global Accessibility Statement](#)

#### Quick Links

[Distributor Inventory](#)  
[Product Cross Reference](#)  
[Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

#### Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Knowledge Base](#)  
[Manage Your Account](#)

#### Keep Me Informed

