

CATALOG LISTING

BZE6-RN18X3

ISSUE

6

REPLACES

29AUG07

PR-22651

REVISIONS

A

C084573

JAK

28 APR 97

B

0017057

VKR

23NOV05

C

0023923

RKP

24AUG06

D

0025947

KML

27OCT06

E

0033014

BS

29AUG07

JAK

21 FEB 97

25 FEB 97

TSM

CHECK

21 FEB 97

25 FEB 97

29AUG07

RASTER

DRAWN



MICRO SWITCH
a Honeywell Division

FED. MFG. CODE 91929

SWITCH – ENCLOSED

CATALOG LISTING

BZE6-RN18X3

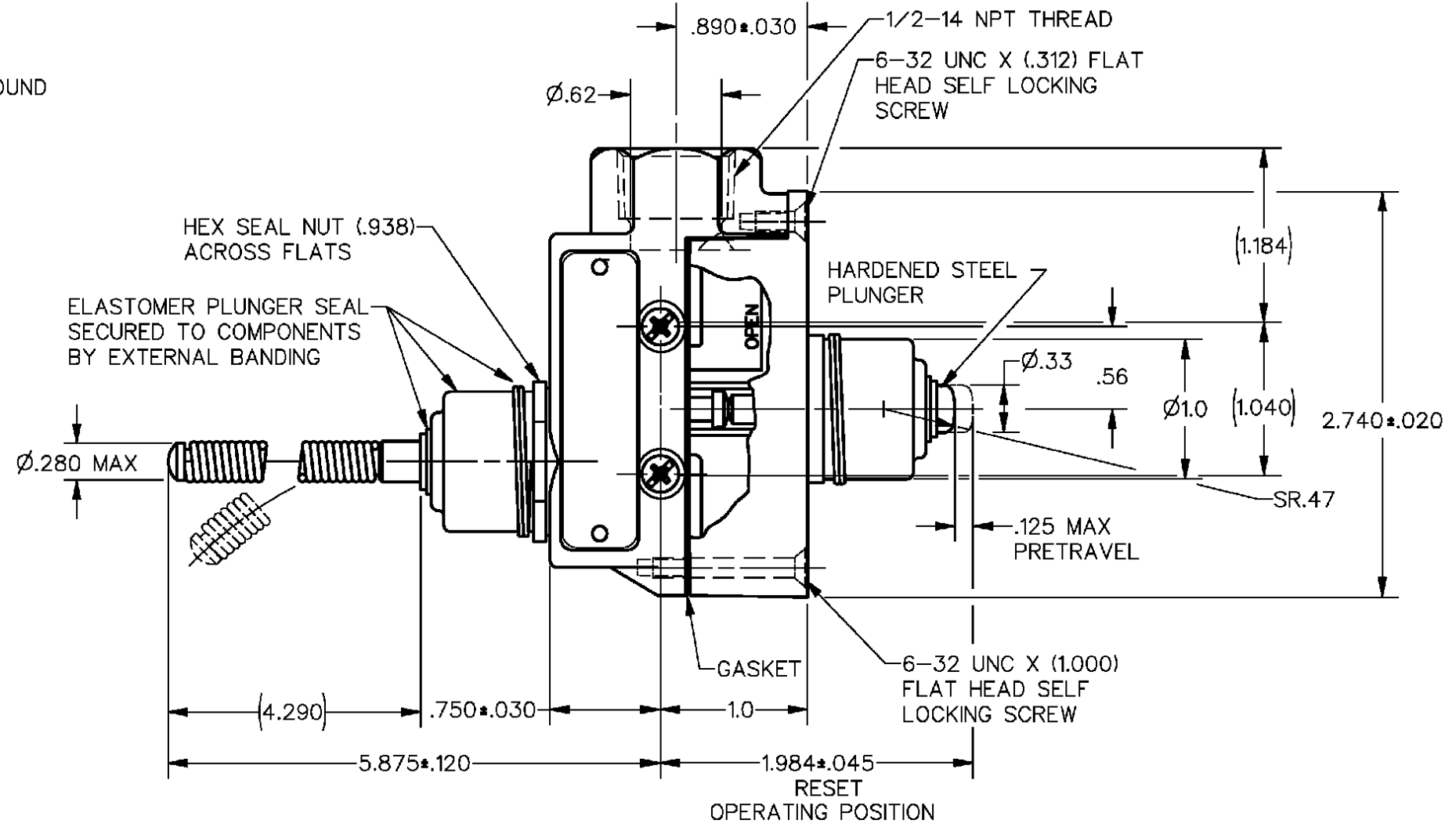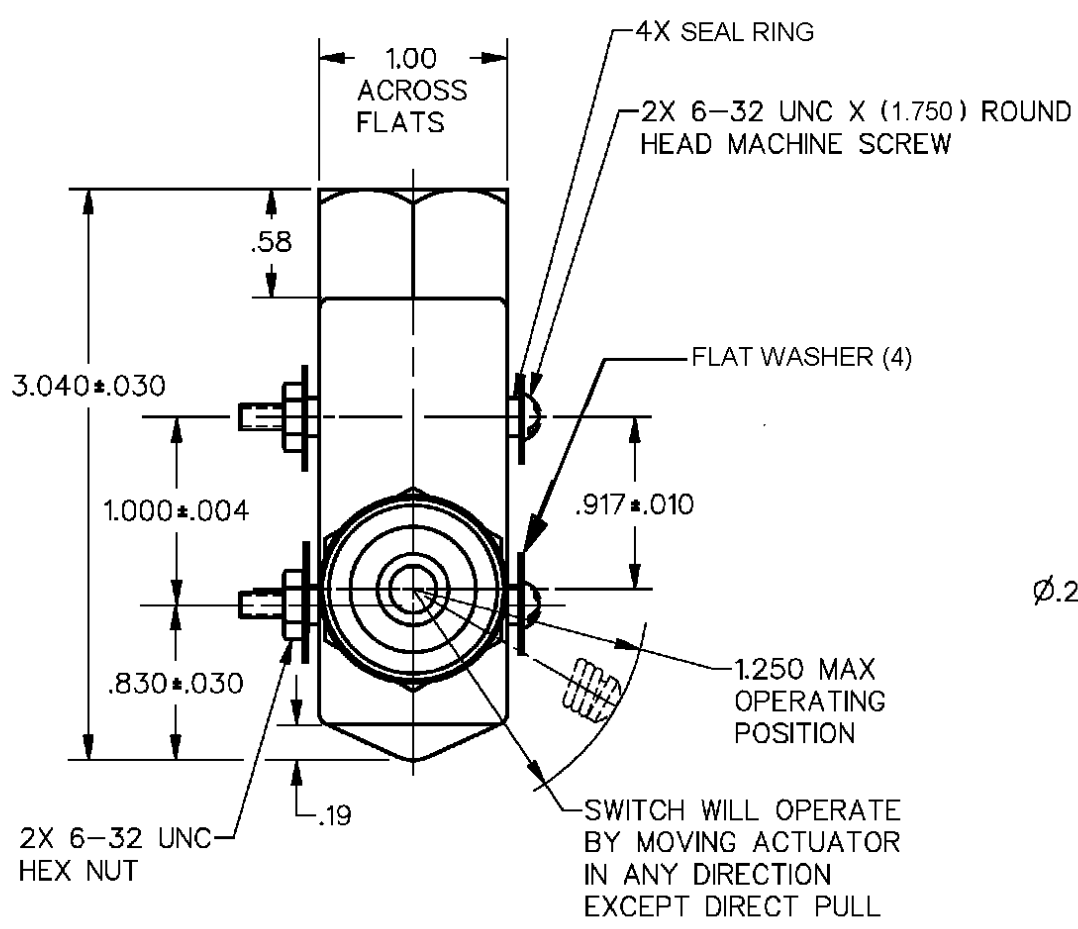

1- SEAL RATING: NEMA1,3,4
IP66

THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF MICRO SWITCH, A DIVISION OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE APPROVAL OF MICRO SWITCH		THIRD ANGLE PROJECTION
CHARACTERISTICS		SCALE FULL
OPERATING FORCE — — — — 12 OZ MAX		DO NOT SCALE PRINT
OPERATING POSITION — — — — 15° MAX		UNLESS OTHERWISE SPECIFIED TOLERANCES ARE
RESET CHARACTERISTICS		ONE PLACE (.0) ± .030
OPERATING FORCE — — — — 12-36 OZ		TWO PLACE (.00) ± .015
OVERTRAVEL — — — — .141 MIN		THREE PLACE (.000) ± .005
SWITCH - BASIC REPLACEMENT — — — BZ-RX61		ANGLES ±
ELECTRICAL DATA		WEIGHT .78 LB
CONTACT ARRANGEMENT S P D T		ANSI Y14.5M-1982 APPLIES
L67 15A 125, 250 OR 480 VAC 1/4HP 125 VAC, 1/2HP 250 VAC 1/2A 125 VDC, 1/4A 250 VDC		
CE 1.5A, 240Vac		