


# 021 SERIES FOR 11/16" MOUNTING HOLE • LIGHT SHIELD

| BASE PART NO.   | VOLTAGE | FIG |
|-----------------|---------|-----|
| 021-0410-29-301 | 2-120   | 1   |

| CAP PART NO. | COLOR   | FIG |
|--------------|---------|-----|
| 021-2900-300 | NO LENS | 2   |


Material & Finish: Chrome Plated Brass

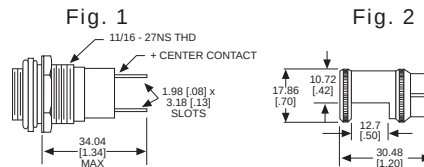

Uses:  
T-3 1/4 MINIATURE  
BAYONET BASE  
INCANDESCENT LAMP

# 052, 081, 095, 135 SERIES FOR 11/16" MOUNTING HOLE • WATERTIGHT

| BASE PART NO.    | VOLTAGE | FIG |
|------------------|---------|-----|
| 081-0410-01-303  | 2-120   | 3   |
| 081-1059-01-303† | 2-120   | 4   |
| 081-1310-01-303  | 2-120   | 5   |

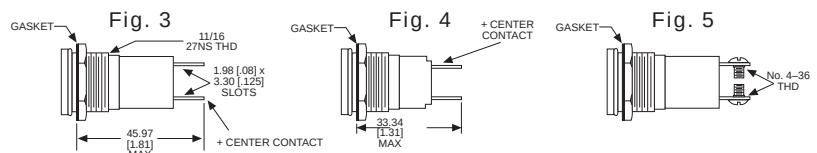

† Part No. 081-1059-01-303 uses T2 Telephone Slide Base Lamp (PSB Type); CSA certified

**\*\* Dialight recommends: transparent lens caps for Based LED;**  
**Clear lens caps for green Based LEDs**

Uses:  
T-3 1/4 MINIATURE BAYONET BASE  
INCANDESCENT LAMP,  
CLUSTER BASED LED\*\* OR  
MULTI-CHIP LED\*\*

| CAP PART NO. * | COLOR | FIG | CAP PART NO. * | COLOR | FIG |
|----------------|-------|-----|----------------|-------|-----|
| 052-3191-003   | RED   | 6   | 081-0433-303   | AMBER | 8   |
| 052-3192-003   | GREEN | 6   | 081-0435-303   | WHITE | 8   |
| 052-3193-003   | AMBER | 6   | 081-0437-303   | CLEAR | 8   |
| 052-3195-003   | WHITE | 6   | 095-3137-003   | CLEAR | 9   |
| 052-3197-003   | CLEAR | 6   | 095-3171-003   | RED   | 9   |
| 081-0111-303   | RED   | 7   | 095-3172-003   | GREEN | 9   |
| 081-0112-303   | GREEN | 7   | 095-3173-003   | AMBER | 9   |
| 081-0113-303   | AMBER | 7   | 095-3175-003   | WHITE | 9   |
| 081-0117-303   | CLEAR | 7   | 135-3237-003   | CLEAR | 10  |
| 081-0135-303   | WHITE | 7   | 135-3271-003   | RED   | 10  |
| 081-0137-303   | CLEAR | 7   | 135-3272-003   | GREEN | 10  |
| 081-0431-303   | RED   | 8   | 135-3273-003   | AMBER | 10  |
| 081-0432-303   | GREEN | 8   | 135-3275-003   | WHITE | 10  |

Material & Finish: Base - Chrome Plated Brass,  
Cap - Polycarbonate with Chrome Plated Bezel on  
the 081 Series Fig. 7 and Fig. 8.


**\*\* Dialight recommends: transparent lens caps for  
Based LED; Clear lens caps for green Based LEDs**

**\*PART NUMBER ORDERING CODE**  
**081-0xxx-303**  
Series Lens Finish:  
1 = Back Frosted  
(Not available in white)  
3 = Transparent\*\*

**\*PART NUMBER ORDERING CODE**  
**095 - 31xx - 003**  
**135 - 32xx - 003**  
Series Lens Finish:  
3 = Transparent\*\*  
7 = Translucent  
(Not available in clear)

# 125 SERIES FOR 11/16" MOUNTING HOLE • OILTIGHT\*

| BASE PART NO.   | VOLTAGE | FIG |
|-----------------|---------|-----|
| 125-0410-11-103 | 2-120   | 11  |
| 125-1310-11-103 | 2-120   | 12  |

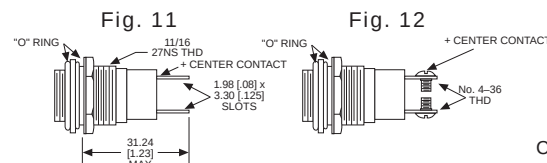

Uses:  
T-3 1/4 MINIATURE  
BAYONET BASE  
INCANDESCENT LAMP,  
CLUSTER BASED LED\*\*,  
OR MULTI-CHIP LED\*\*

| CAP PART NO. | COLOR | FIG | CAP PART NO. | COLOR | FIG |
|--------------|-------|-----|--------------|-------|-----|
| 125-1131-403 | RED   | 13  | 125-1191-403 | RED   | 14  |
| 125-1132-403 | GREEN | 13  | 125-1192-403 | GREEN | 14  |
| 125-1133-403 | AMBER | 13  | 125-1193-403 | AMBER | 14  |
| 125-1135-403 | WHITE | 13  | 125-1195-403 | WHITE | 14  |
| 125-1137-403 | CLEAR | 13  | 125-1197-403 | CLEAR | 14  |

Material & Finish: Base - Nickel Plated Brass  
Cap - Polycarbonate with Chrome Plated Brass Bezel

\* See Page 14 for Oiltight information

Neon and incandescent lamp information on Pages 35 and 36.

Based LED lamp information on Pages 37 through 40.

**\*\* Dialight recommends: transparent lens caps for Based LED; Clear lens caps for green Based LEDs**

Dimensions in mm [inches]

20

Dialight Corporation • 1501 State Route 34 • Farmingdale, NJ 07727 • TEL: (732) 919-3119 • FAX: (732) 751-5778 • www.dialight.com