



Color: natural

Technical data	
Number of spacings	1 -times

Physical data	
Depth	50 mm / 1.97 inches
Pin spacing	5/7.62 mm

Mechanical data	
Suitable	for male and female connectors with CAGE CLAMP® connection

Material data	
Color	natural
Material group	I
Insulation material (main housing)	Glass fiber-reinforced polyamide (PA66 GF)
Flammability class per UL94	HB
Fire load	0.038 MJ
Weight	1.4 g

Commercial data	
Product Group	3 (Multi Conn. System)
PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332117661
Customs tariff number	82055980000



Product Classification		
UNSPSC		27112809
eCl@ss 10.0		27-14-11-92
eCl@ss 9.0		27-14-11-92
ETIM 9.0		EC002848
ETIM 8.0		EC002848
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
RoHS Compliance Status		Compliant,No Exemption


Approvals / Certificates					
General approvals			Approvals for marine applications		
					
Approval	Standard	Certificate Name	Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2	1466354	LR Lloyds Register	IEC 61984	96/20035 (E5)

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 231-159	

Installation Notes	



Conductor termination parallel to CAGE CLAMP® actuation

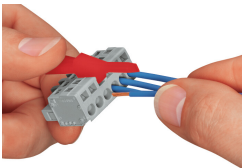

Conductor termination perpendicular to CAGE CLAMP® actuation

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com