




Part Number : [2166121210](#)

Product Description : Mini Cool Edge (MCIO) Left-Exit-to-Mini Cool Edge (MCIO) Left-Exit Cable Assembly, Thumb Release, 16x, 124 Circuits, PCIe 5.0, 30 AWG, with Expando, 167.00mm Length

Series Number : 216612

Status : Active

Product Category : High-Speed I/O Cable Assemblies

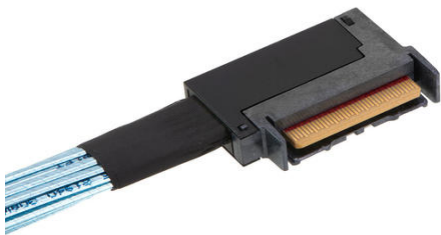

Documents & Resources

Drawings

[2166121210 sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	High-Speed I/O Cable Assemblies
Series	216612
Description	Mini Cool Edge (MCIO) Left-Exit-to-Mini Cool Edge (MCIO) Left-Exit Cable Assembly, Thumb Release, 16x, 124 Circuits, PCIe 5.0, 30 AWG, with Expando, 167.00mm Length
Assembly Configuration	Dual Ended Connectors
Connector to Connector	MCIO-to-MCIO
Product Name	Mini Cool Edge (MCIO)
Type	Internal
UPC	196823242403

Electrical

Data Rate	32.0 Gbps
Voltage - Maximum	30V AC

Physical

Cable Bundling	Woven Braid
Cable Length	167.00mm
Circuits (Loaded)	124
Circuits (maximum)	124
Color - Resin	White
Gender	Plug/Plug
Lock to Mating Part	Yes
Material - Plating Mating	Gold
Material - Resin	Polycarbonate
Orientation	Left-Exit-to-Left-Exit

Release Style	Thumb Release
Single Ended	No
Wire/Cable Type	Twinax

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mini Cool Edge (MCIO) 8x and 16x Right-Angle Connectors	<u>217346</u>

This document was generated on Oct 11, 2025