

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Miniature Circuit Breaker, number of positions: 2, cross section: 1 mm²- 35 mm², AWG: 18 - 2, mounting type: DIN rail: 35 mm

Commercial data

Item number	1019949
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	CL09
Product key	CLA126
GTIN	4055626508399
Weight per piece (including packing)	241.51 g
Weight per piece (excluding packing)	241 g
Customs tariff number	85362010
Country of origin	CN

TMC 72B 60A - Miniature Circuit Breaker



1019949
<https://www.phoenixcontact.com/us/products/1019949>

Technical data

Product properties

Product type	Thermomagnetic device circuit breakers
Product family	TMC 7
Type	DIN rail module, one-piece
Number of positions	2
Mechanical service life	20000

Electrical properties

Service life electrical	6000
-------------------------	------


General

Operating voltage	277 V AC (277/480Y, 240D)
	125 V DC (two poles in series)
Rated current I_N	60 A
Tripping method	TM (thermomagnetic)
Rated short-circuit switching capacity I_{cn}	5 kA (277/480Y, 240D)
	7.5 kA (125 V DC, two poles in series)
Fuse	B (curve)

Connection data

Conductor cross section rigid	1 mm² ... 35 mm²
Cross section AWG	18 ... 2 (converted acc. to IEC)
Conductor cross section flexible	1 mm² ... 35 mm²
Connection method	Screw connection
Tightening torque, min	2 Nm
Stripping length	11 mm ... 12 mm
Conductor cross section flexible max.	35 mm²
Conductor cross section, rigid max.	35 mm²

Dimensions

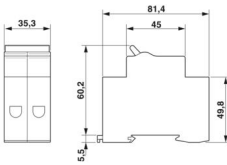Dimensional drawing	
Width	35.3 mm
Height	84.3 mm
Depth	76.6 mm (incl. DIN rail 7.5 mm)

Material specifications

Color	light grey (RAL 7035)
-------	-----------------------

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

	light grey (RAL 7035)
--	-----------------------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP20
Ambient temperature (operation)	-35 °C ... 70 °C
Humidity test	48 h, 95% RH, 40°C (IEC 60068-2-78)
Shock (operation)	30g (11 ms) (IEC 60068-2-11, test Ea)
Vibration (operation)	±0.38 mm (10-57 Hz), 5g (57...500 Hz) (Sinusoidal test to IEC 60068-2-6, Test Fc. 10 frequency cycles per axis)

Standards and regulations

Standards/specifications	UL 1077
Standards/specifications	IEC 60947-2

Mounting

Mounting type	DIN rail: 35 mm
---------------	-----------------

TMC 72B 60A - Miniature Circuit Breaker


1019949

<https://www.phoenixcontact.com/us/products/1019949>



Drawings

Diagram

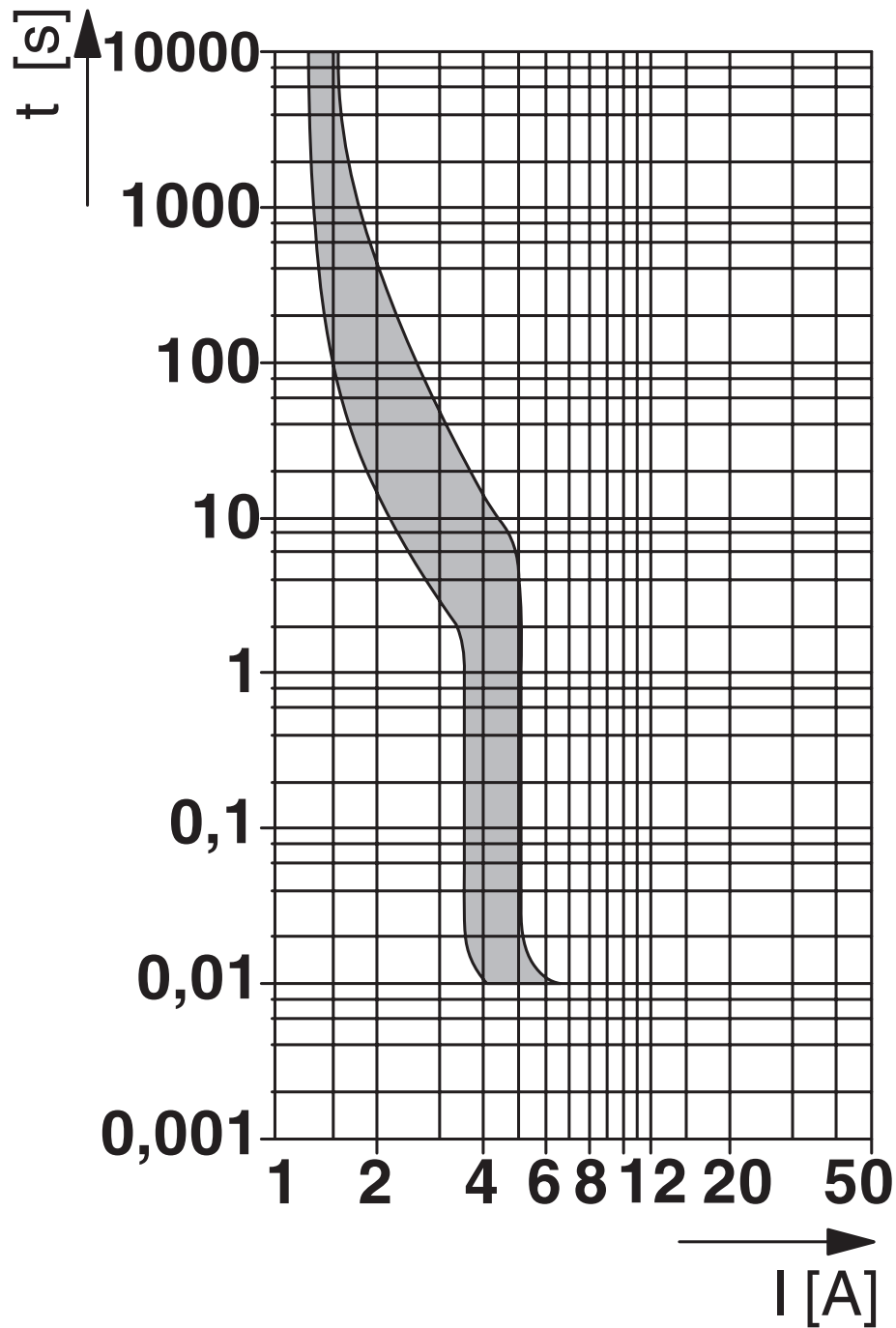


TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



Dimensional drawing

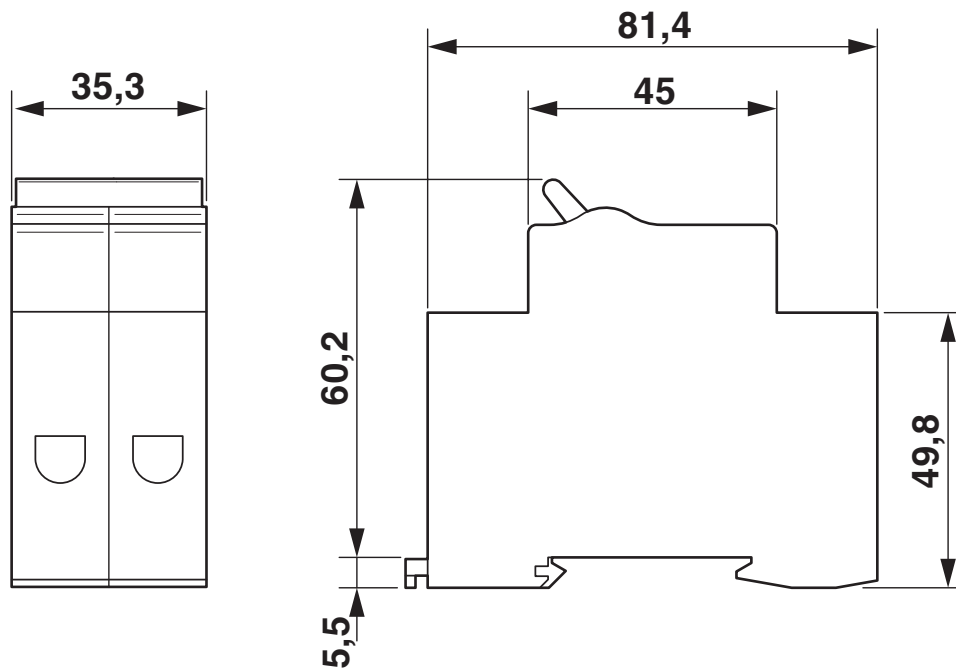

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1019949>



cUL Recognized
Approval ID: FILE E 140459



UL Recognized
Approval ID: FILE E 140459

cULus Recognized

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

Classifications

ECLASS

ECLASS-11.0	27141116
ECLASS-12.0	27141116
ECLASS-13.0	27140401

UNSPSC

UNSPSC 21.0	39121410
-------------	----------

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

TMC 72B 60A - Miniature Circuit Breaker



1019949


<https://www.phoenixcontact.com/us/products/1019949>

Accessories

TMC 7 B2 80 56 C - Wiring bridge

1022236

<https://www.phoenixcontact.com/us/products/1022236>

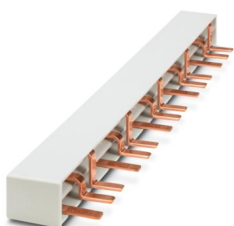


Bus bar for TMC 72... circuit breakers (two phase) 17.8 mm pitch, up to 56 positions. Rated for 80 A (end feed) 600 V AC/DC. UL 508 Listed for connection of UL 1077 rated circuit breakers.

TMC 7 B2 80 46 CA - Wiring bridge

1022235

<https://www.phoenixcontact.com/us/products/1022235>

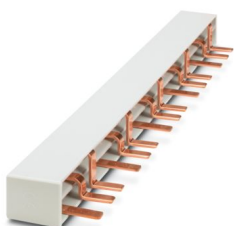

Bus bar for TMC 72... circuit breakers (two phase) 17.8 mm pitch, up to 46 positions. Rated for 80 A (end feed) 600 V AC/DC. UL 508 Listed for connection of UL 1077 rated circuit breakers.

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7 B2/3 TERM - Terminal adapter

1022232

<https://www.phoenixcontact.com/us/products/1022232>



Feeder terminal adapter for TMC 72 or TMC 73 circuit breakers, two- or three-phase bus bars. Rated for 600 V AC/DC 115 A. Wire range 10...1/0 AWG. UL 508 Listed for connection to UL 1077 rated circuit breakers.

TMC 7 B2/3 END CAP - Wiring bridge end cover

1022229

<https://www.phoenixcontact.com/us/products/1022229>



Protective end covers for TMC 7 multi-pole bus bars

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7 B BUS CAP - Protective cover

1022224

<https://www.phoenixcontact.com/us/products/1022224>

Protective covers for TMC 7 single-pole bus bars. Cuttable, five positions, yellow.



TMC 7/8 AUX - Auxiliary Contact

2908219

<https://www.phoenixcontact.com/us/products/2908219>



Auxiliary Contact, number of positions: 1, connection method: Screw, cross section: 1 mm²- 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7/8 ALARM - Alarm Switch

2908220

<https://www.phoenixcontact.com/us/products/2908220>



Alarm Switch, number of positions: 1, connection method: Screw, cross section: 1 mm²- 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 7/8 12VDC SHNT - Thermomagnetic device circuit breaker

2908221

<https://www.phoenixcontact.com/us/products/2908221>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm²- 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7/8 24VDC SHNT - Thermomagnetic device circuit breaker

2908222

<https://www.phoenixcontact.com/us/products/2908222>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 7/8 48VDC SHNT - Thermomagnetic device circuit breaker

2908224

<https://www.phoenixcontact.com/us/products/2908224>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7/8 125VDC SHNT - Thermomagnetic device circuit breaker

2908225

<https://www.phoenixcontact.com/us/products/2908225>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 7/8 120VAC SHNT - Thermomagnetic device circuit breaker

2908226

<https://www.phoenixcontact.com/us/products/2908226>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



TMC 7/8 240VAC SHNT - Thermomagnetic device circuit breaker

2908227

<https://www.phoenixcontact.com/us/products/2908227>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 7/8 277VAC SHNT - Thermomagnetic device circuit breaker

2908228

<https://www.phoenixcontact.com/us/products/2908228>



Thermomagnetic device circuit breaker, number of positions: 1, connection method: Screw, cross section: 1 mm² - 35 mm², AWG: 18 - 2, mounting type: Snaps on to side of circuit breaker

TMC 72B 60A - Miniature Circuit Breaker



1019949

<https://www.phoenixcontact.com/us/products/1019949>

EML (10X4)R - Label

0815583

<https://www.phoenixcontact.com/us/products/0815583>



Label, Roll, white, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: adhesive, lettering field size: 10 x 4 mm, Number of individual labels: 10000

TML (104X3,8)R - Marker strip

0801833

<https://www.phoenixcontact.com/us/products/0801833>



Marker strip, Roll, white, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: adhesive, for terminal block width: 104 mm, lettering field size: 104 x 3.8 mm, Number of individual labels: 2500

TMC 72B 60A - Miniature Circuit Breaker

1019949

<https://www.phoenixcontact.com/us/products/1019949>



SZK PZ2 VDE - Screwdriver

1206463

<https://www.phoenixcontact.com/us/products/1206463>



Screwdriver, PZ crosshead, VDE insulated, size: PZ 2 x 100 mm, 2-component grip, with non-slip grip

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com