

**SCHROFF**

Project - 0 item(s)

MY PROJECT LIST

PRODUCTS

APPLICATIONS

INDUSTRIES

NEW PRODUCTS

CONFIGURATORS

Products ▾

Search



Home > EuropacPRO kit, flexible design, shielded, for backplane mounting



EuropacPRO kit, flexible design, shielded, for backplane mounting

SCHROFF**Catalog Number: 24563-442**[Back To Product](#)

- Rear horizontal rail for backplane mounting with insulation strip
- Supplied as space-saving flat-pack
- Modifications such as cutouts, different finishes or dimensions available
- EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels. Testing in accordance with VG 95373 part 15
- IP 20, in accordance with IEC 60529
- Aluminum construction
- Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1
- Subrack with side panel type F ("flexible"), Front 19" bracket included, depth-adjustable 19" bracket sold separately
- Horizontal rail type "light"

Note:

Individual configuration: large variety of variants in height, width and depth; various guide rails for a wide variety of applications; Interior options; accessories and mounting material

Load:

Up to 11 kg

Shock/vibration:

Up to 2 g

Design:

EuropacPRO, Flexible

EMC Shielding:

Shielded

Type:

Subrack Kit

Description:

shielded

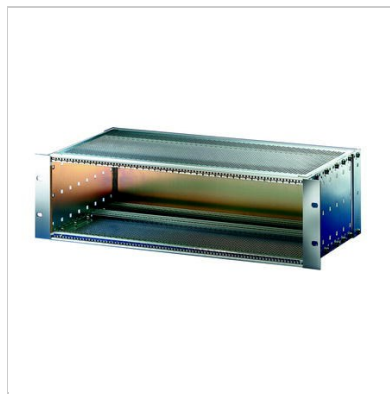
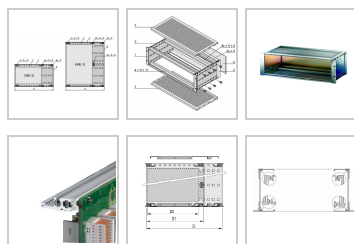


Photo shows 3 U subrack

Other Views

**Select product specifications before modifying or adding to project list or requesting a quote.**

Height-U-defining

6 ▾

Depth-mm-defining

235 ▾

[Clear Selection](#)Quantity [Add Item to Project List +](#)**Documents**

- Main Catalog - EuropacPRO
- User Manual
- User Manual
- 6 U
- User Manual
- EMC test report (textile gasket)

Links

- Test report
- Native CAD files

Technical Data

 
Depth mm	235.0
Depth D mm	235.0
Depth D1 mm	175/235
Height U	6
Width HP	84

Delivery Comprises:

Item	Quantity	Description
------	----------	-------------

1	2	19" support bracket for EMC textile gasket
2	2	Corner profile to rear for EMC textile gasket
3	2	Side panel type F
4 c	1	Centre horizontal rail (ST)
4 a	2	Rear horizontal rail (L-KD)
4	2	Front horizontal rail (L-KD)
4 b	2	Rear horizontal rail (L-ST) for backplane mounting with insulation strip
5	8	Threaded insert (pre-fitted)
6	4	Insulation strip, fixed
7	2	EMC cover plate
8	1	EMC gasketing material (pre-fitted)
9	1	Rear panel
10	1	Assembly kit
11	2	Perforated strip (pre-mounted)
12	1	User manual

Accessories



Perforated rail for connector according to EN 60603-2 (DIN 41612), 84 HP, with thread M2.5, PU 4 pieces

20822-048

Add Item to Project List +



Guide rails, standard, 160 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces

24560-351

 
Add Item to Project List +



Guide rails, standard, 220 mm deep, PBT, UL 94 V-0, red, groove width 2 mm, PU 10 pieces

24560-353

Add Item to Project List +



19" fixing material kit (screw, washer, nut), (8 x screws, 8 x plastic washers, 8 x cage nuts)

21100-435

Add Item to Project List +

EXPLORE	CONTACT	DOWNLOAD
About Us	Customer Service	Download Center
Services & Capabilities	Find a Sales Office or Distributor	Reference Projects
News & Events	Global Locations	Videos
Newsletter Subscriptions	Product Compliance & Certifications	Product Configurators
Strategic Partnerships	Partner Login	Warranties and Terms of Sale & Procurement
Investor Relations		

