



## Pre-printed cable markers

### Ovalgrip, slide on, straight cut

The Ovalgrip range consists of pre-printed markers that slide easily onto cables and wires. The markers are ideally suited to panel building, mass transit, utilities, telecommunications and electrical contracting.

These markers are supplied as standard on a disk / reel.

They are available as a standard in yellow material marked in black, and international resistor colour code. Characters are 0-9, A-Z and standard electrical symbols.

White material marked in black available on special request.


AT1 Arrowtags will fit 7 size 50 markers.

AT2 Arrowtags will fit 8 size 85 markers.

AT3 Arrowtags will fit 14 size 85 markers.

### Features and benefits


- Oval shaped markers designed to fit AT1, AT2 or AT3 (depends on Ovalgrip size)
- Ideal for use in maintenance and repair and fixed with cable ties
- Direct application to wire and cable before termination is also recommended
- Traditional wire marking available in yellow, white and colour code

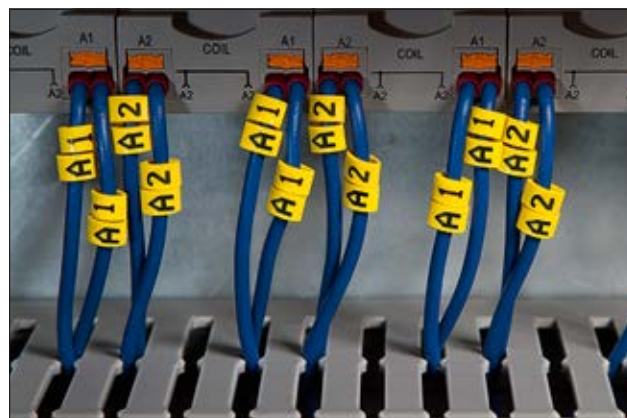

A simple idea for complex marking needs.

|                              |                                                 |
|------------------------------|-------------------------------------------------|
| <b>MATERIAL</b>              | Flexible Polyvinyl Chloride, cadmium free (PVC) |
| <b>Operating Temperature</b> | -65 °C to +105 °C, intermittent +135 °C         |
| <b>Flammability</b>          | UL 94 V0 (3 mm)                                 |

RoHS

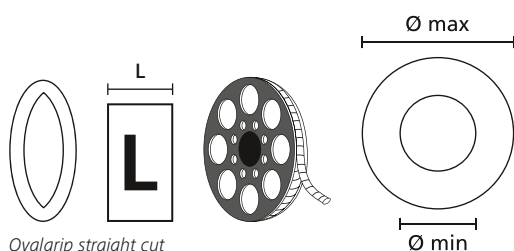

Ovalgrip straight cut



The products have been tested in-house according to UL224.




For details on Arrowtags please see page 491.

| TYPE   | Bundle Ø min. | Bundle Ø max. | Length (L) | Pack Cont. | For Size |
|--------|---------------|---------------|------------|------------|----------|
| HODS50 | 1.7           | 3.6           | 4.0        | 1,000 pcs. | AT1      |
| HODS85 | 1.8           | 6.3           | 4.5        | 1,000 pcs. | AT2/AT3  |

All dimensions in mm. Subject to technical changes.

 Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available. More colours on request.



### Pre-printed cable markers

Ovalgrip, slide on, straight cut

| HODS50 |             |
|--------|-------------|
|        | Article-No. |
| A      | 531-15014   |
| B      | 531-15024   |
| C      | 531-15034   |
| D      | 531-15044   |
| E      | 531-15054   |
| F      | 531-15064   |
| G      | 531-15074   |
| H      | 531-15084   |
| I      | 531-15094   |
| J      | 531-15104   |
| K      | 531-15114   |
| L      | 531-15124   |
| M      | 531-15134   |
| N      | 531-15144   |
| O      | 531-15154   |
| P      | 531-15164   |
| Q      | 531-15174   |
| R      | 531-15184   |
| S      | 531-15194   |
| T      | 531-15204   |
| U      | 531-15214   |
| V      | 531-15224   |
| W      | 531-15234   |
| X      | 531-15244   |
| Y      | 531-15254   |
| Z      | 531-15264   |

| HODS50 |             |
|--------|-------------|
|        | Article-No. |
| 0      | 531-15274   |
| 1      | 531-15284   |
| 2      | 531-15294   |
| 3      | 531-15304   |
| 4      | 531-15314   |
| 5      | 531-15324   |
| 6      | 531-15334   |
| 7      | 531-15344   |
| 8      | 531-15354   |
| 9      | 531-15364   |
| .      | 531-00174   |
| /      | 531-00175   |
| ±      | 531-00176   |
| +      | 531-00451   |
| -      | 531-00452   |
| 0      | 531-15365   |
| 1      | 531-15366   |
| 2      | 531-15367   |
| 3      | 531-15368   |
| 4      | 531-15314   |
| 5      | 531-15370   |
| 6      | 531-15371   |
| 7      | 531-15372   |
| 8      | 531-15373   |
| 9      | 531-15374   |

| HODS85 |             |
|--------|-------------|
|        | Article-No. |
| A      | 531-07935   |
| B      | 531-07936   |
| C      | 531-07937   |
| D      | 531-07938   |
| E      | 531-07939   |
| F      | 531-07940   |
| G      | 531-07941   |
| H      | 531-07942   |
| I      | 531-07943   |
| J      | 531-07944   |
| K      | 531-07945   |
| L      | 531-07946   |
| M      | 531-07947   |
| N      | 531-07948   |
| O      | 531-07949   |
| P      | 531-07950   |
| Q      | 531-07951   |
| R      | 531-07952   |
| S      | 531-07953   |
| T      | 531-07954   |
| U      | 531-07955   |
| V      | 531-07956   |
| W      | 531-07957   |
| X      | 531-07958   |
| Y      | 531-07959   |
| Z      | 531-07960   |

| HODS85 |             |
|--------|-------------|
|        | Article-No. |
| 0      | 531-07925   |
| 1      | 531-07926   |
| 2      | 531-07927   |
| 3      | 531-07928   |
| 4      | 531-07732   |
| 5      | 531-07930   |
| 6      | 531-07931   |
| 7      | 531-07932   |
| 8      | 531-07933   |
| 9      | 531-07934   |
| .      | 531-00384   |
| /      | 531-07961   |
| ±      | 531-00386   |
| +      | 531-07924   |
| -      | 531-07923   |
| 0      | 531-07728   |
| 1      | 531-07729   |
| 2      | 531-07730   |
| 3      | 531-07731   |
| 4      | 531-07732   |
| 5      | 531-07733   |
| 6      | 531-07734   |
| 7      | 531-07735   |
| 8      | 531-07736   |
| 9      | 531-07737   |

