





DB UNLIMITED

Part Number:	SC700208-1	DRAWN	9/4/2019
		CJ	
		CHECKED	9/4/2019
Description:	Dynamic Speaker	C.H.	
		APPROVED	9/4/2019
		C.E.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com			


Top View

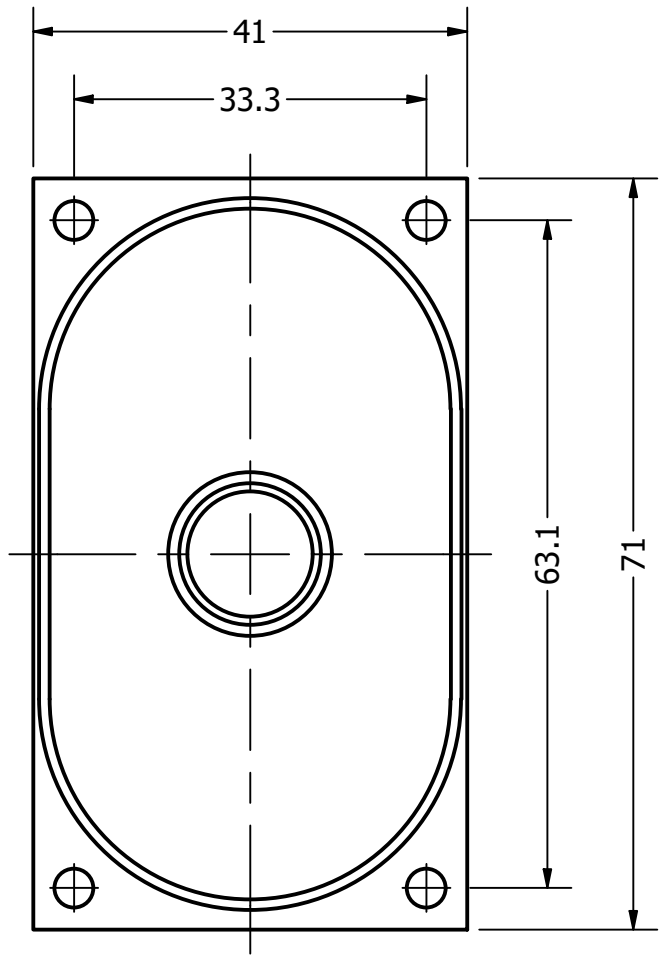

Side View

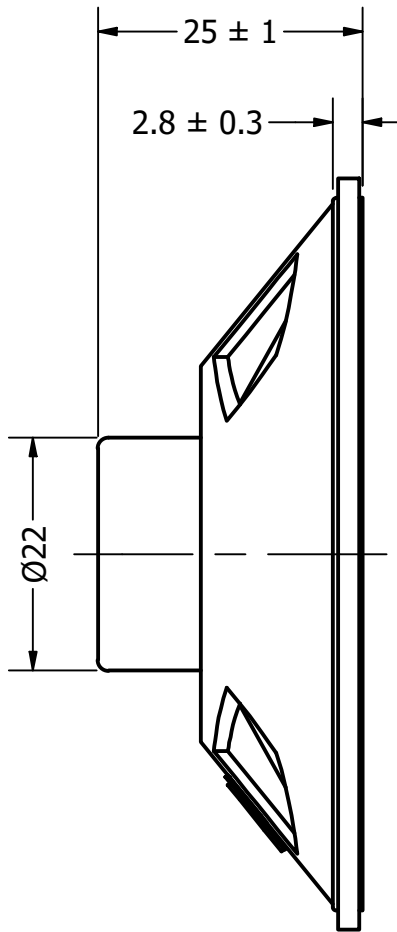

Bottom View

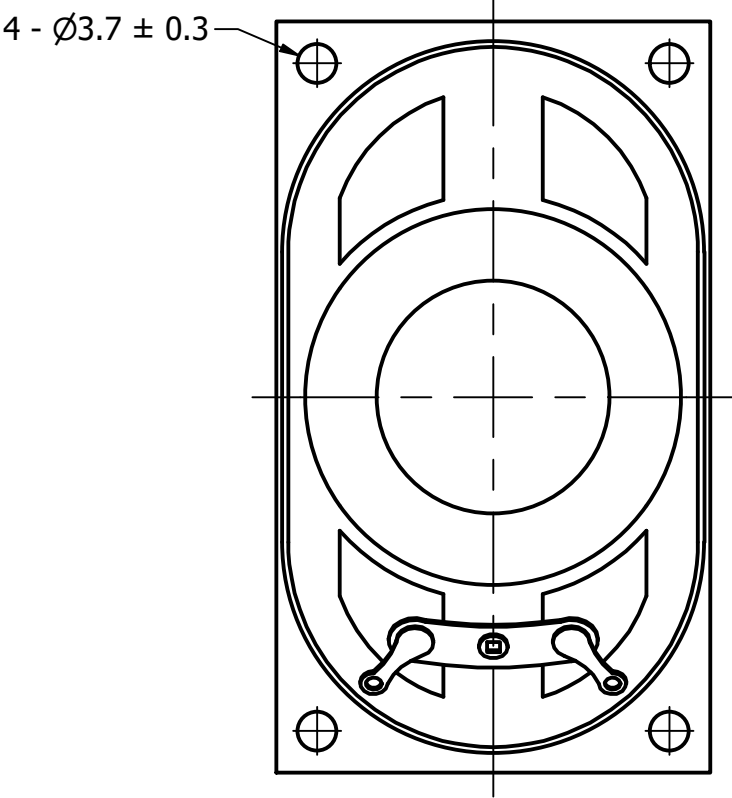

Items	Specifications	Conditions				
Sound Pressure Level	100	dB (@ 1W/10cm)				
Resonant Frequency	280 ± 20%	Hz				
Frequency Range	200 ~ 20,000	Hz				
Nominal Power	3	W				
Max. Power	5	W				
Impedance	8	Ω				
Cone Material	Cloth					
Mount Type	Frame Mount					
Storage Temperature	-40 ~ +80	°C				
Operating Temperature	-40 ~ +80	°C				
Weight	38	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	2/8/2014	J.S.
1	Updated drawing to new template, frequency, SPL, temps	9/4/2019	C.E.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	