
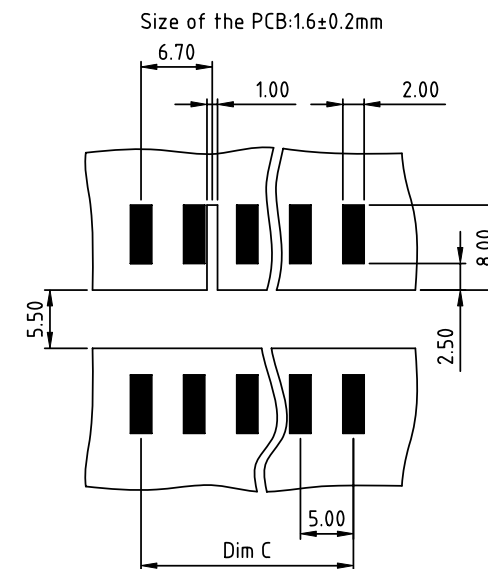
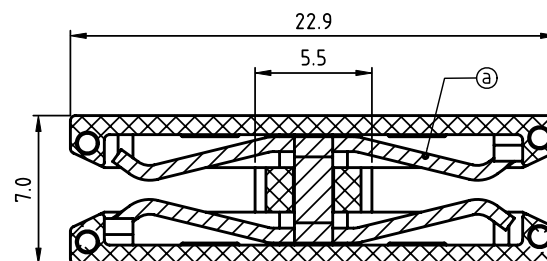


PRODUCT NUMBER	PITCH
KFxx70x000J0G	5.00 mm

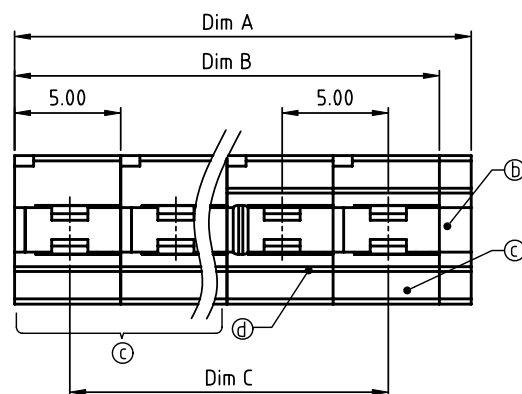

RECOMMENDED P.C.B LAYOUT
TOP VIEW

Material:

- Item**③**Female contact: PhBz(CuSn), Tin plated
- Item**④**Terminal Cover: Thermoplastic (UL94V-0)
- Item**⑤**Terminal housing: Thermoplastic (UL94V-0)
- Item**⑥**Terminal housing (B Type) : Thermoplastic (UL94V-0)

Electrical cULus

- Voltage rating: 300VAC
- Current rating: 10A
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +115°C

Dimension

Dim A	$N \times 5.0 + 1.50$
Dim B	$N \times 5.0$
Dim C	$(N-1) \times 5.0$

N=Number of poles

Poles	Tolerance
2p-6p	±0.15
7p-13p	±0.20
14p-18p	±0.30
19p-24p	±0.35

PART NO.: KF xx 70 x 0 00J0 G

No. of poles		Color	RoHS compliant (lead<4%) In copper Alloy
End stackable	0	Black (RAL9005)	
No. of poles	2	Red (RAL3001/D)	
02	2 poles	3 Orange(RAL2011/P)	
03	3 poles	4 Yellow(RAL1018/A)	
...	...	5 Green(RAL6018/T)	
24	24 poles	6 Blue (RAL5015/A)	
		8 Grey(RAL7035/D)	
		9 White(RAL1102)	
		C Green(RAL6018/U)	

[illegible]