

Quick Links

Cross reference

RoHS/LF P/N Search

Industry Standards

Alphabetical List

Documentation

3D model search

Customer drawing search


Multi Selection Search

Search by category

Start > Search=10135175-06110LF* > 10135175-06110LF

10135175-06110LF

10135175-06110LF - Minitex® 1.5mm : Minitex® 1.5mm Wire to Board Plug HSG, 6 positions

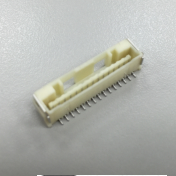

ACTIVE

RoHS Compliant

Distributor Stock

Print Datasheet

FCI Brings You More

Contact our sales/technical support

Sample request

Customer drawing

Product Environmental Compliance Report

Specifications

Download document

General Dimensional Electrical Mechanical Physical Approvals / Certifications Other Features	
General	
Number of contacts	6
Series	10135175
Dimensional	
Pitch	1.5 mm
Electrical	
Withstanding Voltage	500V AC
Current rating	Up to 2.0 AMP
Resistance (Contact)	20m ohms Max
Resistance (Insulation)	500MQ min
Voltage rating	100VAC/DC
Mechanical	
Durability (Mating cycles)	30 Cycles
Insertion force	Refer to product spec.
Withdrawal Force	Refer to product spec.
Physical	
Color (Housing)	Natural
Material (Housing)	Thermoplastic, UL 94V-0
Temperature (Range)	-25°C to +85°C
Approvals / Certifications	
Approvals / Certifications	UL E66906
Other Features	
Packaging (Type)	Tape & Reel

Disclaimer : The information above is for reference only. For more technical details, refer to product specification and application specification.