

BSCH0016080827NJ00

Search by :

Part Number

Characteristics

Cross reference



MP



Multilayer-STD

Series Pdf

RoHSREACHCoC

ICP Report

Product detail

Structure	Multilayer
L(mm) ±	1.6±0.15
W(mm) ±	0.8±0.15
T(mm) ±	0.8±0.15
Size Code (JIS/EIA)	1608/0603
Inductance(nH)	27
Unit	nH
Tolerance(±%)	5
Test Frequency(L)	100 MHz,200 mV
Q Min	12
Test Frequency(Q)	100 MHz,200 mV
SRF(MHz)Typ	1900
RDC(Ω)Max	0.45

Operating Temperature

−55°C~125°C(Including self - temperature rise)

Part Numbering


Dimensions

Packing

Recommended Pattern

Electrical Characteristics

S Parameter

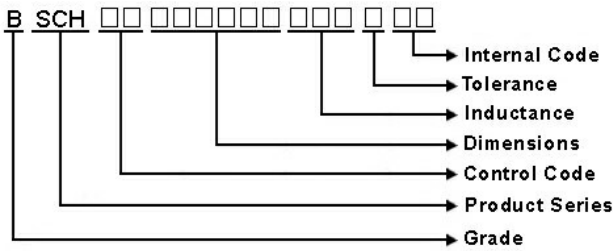

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards

Investor

[Financial Information](#)

[Corporate governance](#)

[Stakeholder Contacts](#)

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.