

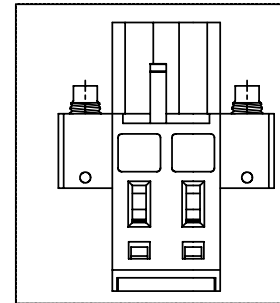
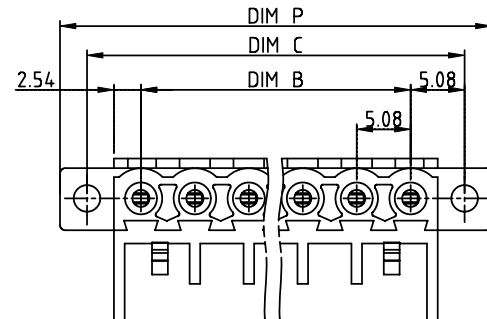


PRODUCT NUMBER	PITCH
HNxx50x200J0G	5.08 mm

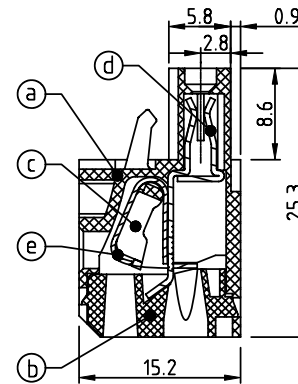

2P

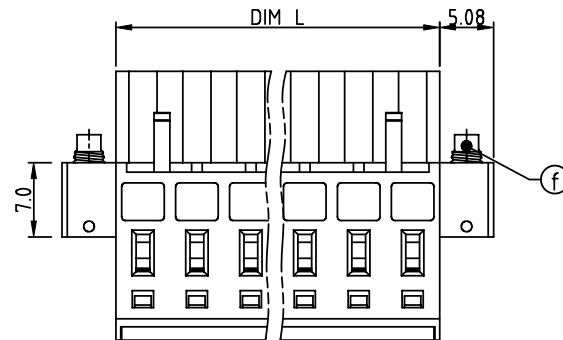

Material:

- Item**Ⓐ**Terminal body:Thermoplastic (UL94V-0)
- Item**Ⓑ**Terminal cover:Thermoplastic (UL94V-0)
- Item**Ⓒ**Terminal spacer:Thermoplastic (UL94V-0)
- Item**Ⓓ**Female contact:PhBz (CuSn) Tin plated
- Item**Ⓔ**Spring clamp:Stainless Steel
- Item**Ⓕ**Flange screw:Steel Zinc plating M2.5

Electrical: cULus

- Voltage rating: 300VAC
- Current rating: 10A
- Wire range:
- Solid wire(AWG): 12-26
- Stranded wire(AWG): 14-26
- Wire strip length: 9-10mm
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +115°C
- Safety Approval:  US

PART NO.: HN xx 50 x 2 00J0 G

DIMENSION
Dim P=(N-1)×5.08+15.24
Dim L=(N-1)×5.08+5.08
Dim B=(N-1)×5.08
Dim C=(N-1)×5.08+10.16

N=Number of poles

Poles	Tolerance
2P-6P	± 0.15
7P-12P	± 0.25
13P-18P	± 0.35
19P-24P	± 0.40

Solid block	
No. of poles	
02	2 poles
03	3 poles
...	...
24	24 poles

	Color
0	Black (RAL9005)
2	Red (RAL3001/D)
3	Orange(RAL2011/P)
4	Yellow(RAL1018/A)
5	Green(RAL6018/T)
6	Blue (RAL5015/A)
8	Grey(RAL7035/D)
9	White(RAL1102)
C	Green(RAL6018/U)

RoHS compliant
(lead<4%)
In copper Alloy

[illegible]