

Han-Modular Compact carrier hood

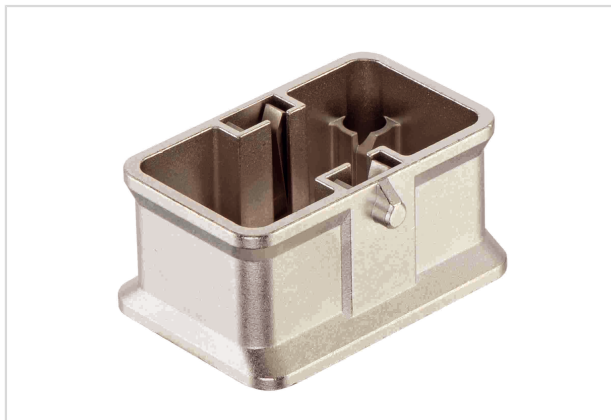


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 0311
Specification	Han-Modular Compact carrier hood
HARTING eCatalogue	https://b2b.harting.com/09140010311

Identification

Category	Hoods/Housings
Series of hoods/housings	Han-Modular® Compact
Type of hood/housing	Carrier hood

Version

Locking type	Single locking lever
Size	Modular Compact

Technical characteristics

Stripping length	10 mm PE contact
Tightening torque	1 Nm PE screw
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500
Degree of protection acc. to IEC 60529	IP65 in locked position

Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Nickel plated
Material (seal)	NBR
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No



Pushing Performance

Material properties

REACH ANNEX XIV substances	No
----------------------------	----

REACH SVHC substances	No
-----------------------	----

Specifications and approvals

Specifications	IEC 61984
----------------	-----------

CE	Yes
----	-----

Commercial data

Packaging size	10
----------------	----

Net weight	60 g
------------	------

Country of origin	Germany
-------------------	---------

European customs tariff number	85389099
--------------------------------	----------

eCl@ss	27440202 Shell for industrial connectors
--------	--