

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0194200012
Status: Obsolete
Description: MX150L™ Female Terminal for 18-22 AWG Wire, Gold Plated

Documents:
[Drawing \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Crimp Terminals
Series	19420
Application	Power
Comments	UL EI52602
Crimp Quality Equipment	Yes
Product Name	MX150L™


Physical

Flammability	94V-0
Gender	Female
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Packaging Type	Bag
Plating min - Mating	0.762µm (30µ")
Plating min - Termination	2.540µm (100µ")
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.36-2.74mm (.093-.108")
Wire Size AWG	18, 19, 20, 22
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Product Specification	PS-19417-001
Sales Drawing	SD-19420-001

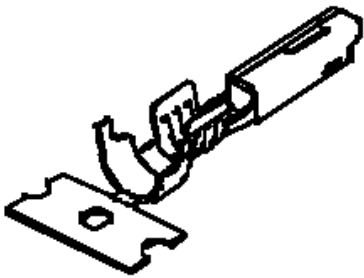

Series
image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[19420Series](#)

Mates With
[19417](#)

Use With
[19418](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimp Tool	0638114400
Hand Crimp Tool	0638117600
Manual Extraction Tool	0638131500

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION