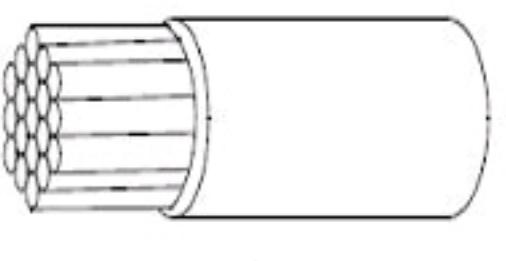


## 22759/32-28-4 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064\_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d\_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661\_img.jpg\) Email](#)

### Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

22759/32-28-4

TE Internal Number: 829202-000

[Active](#)[!\[\]\(4f6bf54ae7e4144a72d78316053e412d\_img.jpg\) Add to My Part List](#)[!\[\]\(3342c215b2a8b663596a81468d5dc314\_img.jpg\) Request Sample](#)[!\[\]\(56549452e01ca28bdf2500ced9653143\_img.jpg\) Find Similar Products](#)[!\[\]\(1f56542a42e2413e44a2b2023033aa2e\_img.jpg\) Buy Product](#)

### Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

### Documentation & Additional Information

**Product Drawings:**

- [Wire, Radiation-Crosslinked, Modified, ETFE-Insulate...](#) (PDF, English)

**Related Products:**

- [Tooling](#)

**Catalog Pages/Data Sheets:**

- None Available

**Product Specifications:**

- None Available

**Application Specifications:**

- None Available

**Instruction Sheets:**

- None Available

**CAD Files:**

- None Available

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

**Product Type Features:**

- [Cable Type](#) = Spec 55
- [Cable Style](#) = Primary
- Number of Conductors = 1

**Conditions for Usage:**

- Temperature Range (°C) = -65 - +150
- Wire Size - Details = 28 AWG 0.089 mm<sup>2</sup>, 0.00014 in<sup>2</sup>, 7 x 36 AWG

**Electrical Characteristics:**

- Voltage Rating (VAC) = 600

**Operation/Application:**

- Application = General Purpose - Lightweight

**Body Features:**

- Wire Size (AWG/CM) = 28 AWG
- Conductor Type = Tin-Plated Copper
- Wire Color = Yellow
- Nominal Outside Diameter (mm [in]) = 0.69 [0.027]
- Wire Diameter (mm [in]) = 0.69 [0.027]
- Conductor O.D. (mm [in]) = 0.38 [0.015]

**Packaging Features:**

- Wire Source = United States

**Industry Standards:**

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/32-28-4
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

**Other:**

- Brand = Raychem

**Corporate Information**[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)**Quick Links**[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)**Customer Support**[Email or Chat With Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage your Account](#)**Keep Me Informed**

Receive TE News, Events &amp; Technology Updates

Enter your email address  