


PRODUCT TOPCATEGORYSPECIFICATIONSINDUSTRIESSERIES NAME

Enter Keyword, Product name or HRS code.

SEARCH

Product Top > DF3 series > DF3EA-8P-2H(50)

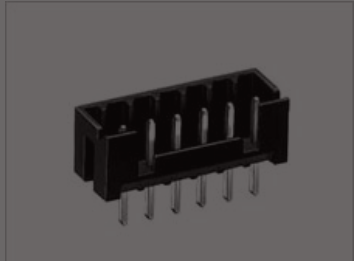

Detailed Specifications

RoHS

- Product Numbers by Series
- Find Mating Connectors
- Part Number Configuration

DF3EA-8P-2H(50)

Product	DF3EA-8P-2H(50)
Series	DF3
Connector Type	Header
Industry Standard	JIS, IEC
Number of Positions	8
Number of Rows (Interface)	1

Detailed Specifications

Last Updated On Dec. 9, 2016

Product information	
Part No.	DF3EA-8P-2H(50)
CL No.	CL0543-0335-0-50
Basic information	
Connector Type	Header
Industry Standard	JIS, IEC
Number of Positions	8
Number of Rows (Interface)	1
Mounting Pitch	2 mm
Contact Pitch	2 mm
Rated Current	3 A
Rated Voltage (AC)	AC 250 V
Rated Voltage (DC)	DC 250 V
Mating/Unmating Cycles	50
Mounting Style	SMT
Connector Orientation	Right angle

Download

DRAWING(3D)

more

ADD TO MY LIST

REQUEST FOR SAMPLE

CONTACT US

CHECK STOCK

Print this page

Send this page

Send this page

Browsing History

3D model of the DF3EA-8P-2H(50) connector.

Series: DF3

Product: DF3EA-8P-2H(50)

Contact Plating	Gold
Operating Temperature	105 to -55 °C
Glow Wire Compliant	Yes
▸ Mechanical Specifications	
▸ Electrical Specifications	
▸ Dimensional Information	
▸ Packaging Specifications	

Download

Catalog	Product Series Catalog	 DOWNLOAD
Data Sheet	Drawing (2D)	Not Available  CONTACT
	3D Model (IGES)	 DOWNLOAD
	3D Model (STEP)	 DOWNLOAD
	Specification Sheet	Not Available  CONTACT

*I need help with a product or information

- [Product Top](#)[Global Site](#)
- [About Us](#)[Terms of use](#)
- [Specifications](#)
- [Industry](#)
- [Series Name](#)
- [Partners](#)

SUPPORT

- [FAQ](#)
- [CONTACT US](#)



© 1999-2017 HIROSE ELECTRIC CO., LTD. All Rights Reserved.

