


Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- X-Lok >
- M Series >
- FLOS & FLOS+ >
- Power >
- RBL >
- HS-Lok >
- NMEA 2000 >
- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >

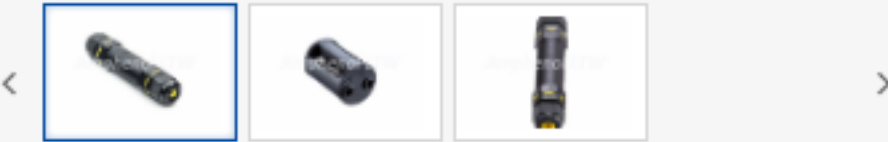

SC-L-PG13-02-YW

- Operating Temperature: -40°C ~ +105°C
- Transmission Speed: N/A
- Shielded: Plastic, Non-shielded
- Jacket Material: N/A
- Certificate: CSA, UL2238, UL50e

You must login first for view the price

Quantity

-1+

Add to Cart

Inquiry

Can't find? [Customize your part](#)

Specifications		Download / CAD	
Nominal Current 20A		Connector Type Field Installable	
Shielded Plastic, Non-shielded		No. of Contacts 02	
Connector Gender N/A		Backshell N/A	
Mating Style Screw Thread		IP Rating IPX8	

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

- FICX PG11
- FICX PG12
- FICX PG13
- FICX PGT2
- FICX UL11
- FICX UL12
- FICX UL13
- FICX ULT2
- M20
- M32
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

Assembly Style Screw-in
<div> More Options</div>

People Also Bought

