


Product Line

- Single Pair Ethernet >
- ZConnect >
- Ceres >
- Accessory
- Large Size
- Macro Size
- Middle Size
- Mini Size
- Others (GBD)
- Others (MAB)
- Others (PLD)
- Standard Size
- X-Lok >
- M Series >
- FLOS & FLOS+ >
- Power >
- RBL >
- HS-Lok >
- NMEA 2000 >

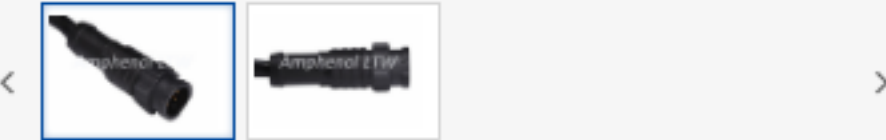

AU-05BFFM-SL7A01

Operating Temperature: -20°C ~ +80°C

Transmission Speed: N/A

Shielded: Plastic, Non-shielded

Jacket Material: PVC

Certificate: N/A

You must login first for view the price

Quantity

-1+

 Check Stock

 Add to Cart

 Inquiry



Can't find? [Customize your part](#)

Mating Pair & Accessories

Connector Type

 Search

ABOUT AMPHENOL LTW

SUPPORT

PARTNERS

DOWNLOAD CENTER

FEEDBACK

- Heavy Duty Shielded >
- RJ >
- USB >
- SSL >
- HDMI >
- DVI >
- Fiber Optic >
- RF >
- Cable Joiner >
- Cable Gland >
- Pressure Relief Vent >
- LED Light Guide >
- D-Sub >

 Add to Cart

 Inquiry

Specifications		Download / CAD	
Nominal Current		Connector Type	
2A		Overmolded	
Shielded		No. of Contacts	
Plastic, Non-shielded		05	
Connector Gender		Backshell	
Female		Straight	
Mating Style		IP Rating	
Screw Thread		IPX7	
Assembly Style			
N/A			
 More Options			

People Also Bought

