

You are here: [Products](#) » [Heatsinks f.cool](#) » [Profile heatsinks and fluid coolers](#) » [Extruded heatsinks for lock-in retaining spring](#) » [SK 514 ...](#) » **SK 514**



▼ Heatsinks f.cool

- ▼ Profile heatsinks and fluid coolers
 - Standard extruded heatsinks
 - Extruded heatsinks for lock-in retaining spring
 - Extruded heatsinks for PCB mounting
 - Extruded heatsinks for DC/DC converter
 - Retaining springs for transistors
 - U-Extruded heatsinks
 - Die-cast heatsinks
 - Fin coolers
 - Fluid coolers
 - Aluminium flat-, quadrangular-, angled-, U- and T-profiles
- ▶ Heatsinks and active heatsinks for processors
- ▶ Board Level heatsinks
- ▶ Cooling aggregates
- ▶ Accessories for electronic components

▶ Cases f.case

▶ Connectors f.con

Extruded heatsinks for lock-in retaining spring


SK 514 ...

SK 514 37,5 SA

30 x 52 mm, for THFU 1-4+6, profile threads

Data sheet

add to request

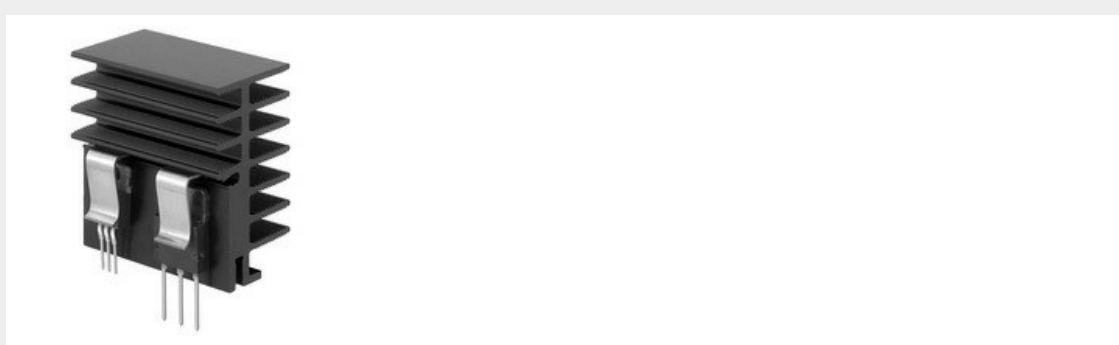

Features

Technical Drawing

Service

Accessories / related products

width	30 mm
height	52 mm
plate thickness	8 mm
length	37.5 mm
thermal resistance R_{th}	5.3 - 1.6 K/W
surface	black anodised