

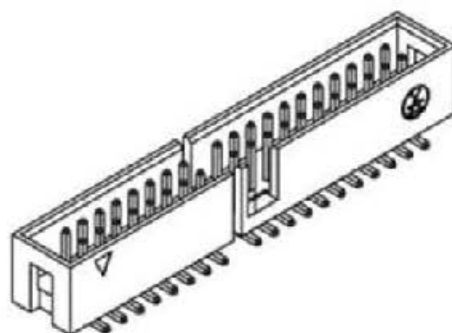
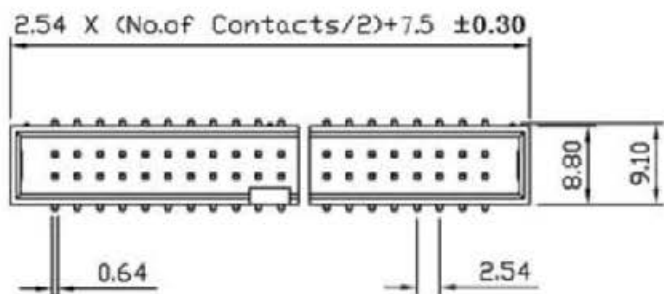


A

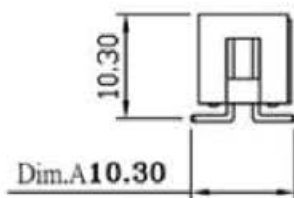



B

C

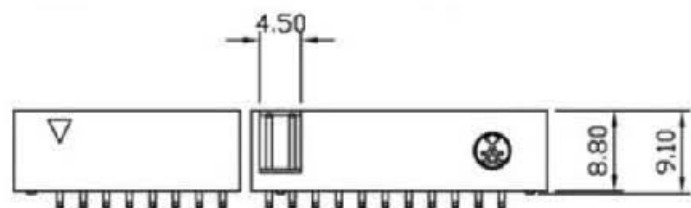

D

E

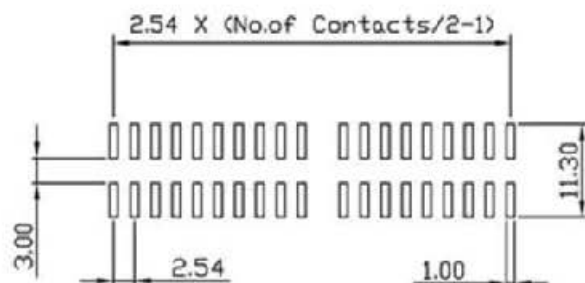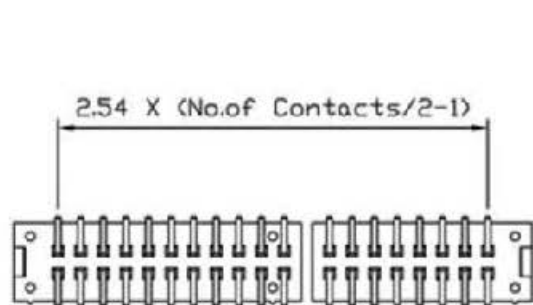

Current Rating: 3 Amps
Insulator Resistance: 5000 Megohms min
Dielectric Withstanding: AC 1000V
Operating Temperature: - 40° ~ +105° C
Max Processing Temp: 230° C for 60 seconds
Contact Material: Copper Alloy
Insulator Material: Polyester, UL 94V-0
Standard: PA6T
Underplate: Nickel
Contact Area: 1u"~30u" Selective Gold
Solder Tails Area: 100u" Tin/Lead Free(Brighten Tin/Matte Tin)

F

Tolerance: ± 0.2

Unit: MM

[illegible]

Item No.	
AWHWxx-G-SMD-R	
Title Box Header, Pitch 2.54MM, SMT Type, PCB Mount	
Drawing No.	rev00
Replace	Sheet



ASSMANN
WSW components