


**Part Number :** [152660343](#)

**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 32 Circuits

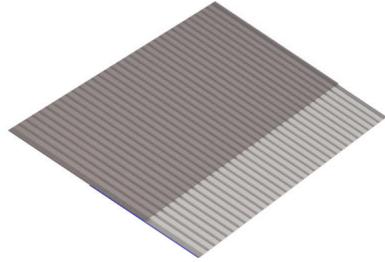

**Series Number :** 15266

**Status :** Active

**Product Category :** Flat-Flexible Cable (FFC)

## Documents & Resources

### Drawings

[152660343\\_sd.pdf](#)

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[PS-15266-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	ⓘ per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15266
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Tin (Sn) Plating, 32 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	884982438033

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

### Physical

Cable Length	102.00mm
Circuits (Loaded)	32
Contact Layout Type	A (same side)
Design Feature	Flexible
Material - Plating Mating	Tin
Net Weight	1.077/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 32 Circuits, Copper Alloy, Tin-Bismuth Plating	<a href="#"><u>5019513200</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 32 Circuits, Tin-Bismuth Plating	<a href="#"><u>525593272</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 32 Circuits, Tin-Bismuth Plating	<a href="#"><u>541043296</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 32 Circuits, Tin-Bismuth Plating	<a href="#"><u>541323297</u></a>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 32 Circuits	<a href="#"><u>781193210</u></a>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 32 Circuits	<a href="#"><u>781273210</u></a>

This document was generated on Sep 11, 2025