




[Custom Capabilities](#)[Test Accessories](#)[Plugs, Jacks, Posts](#)[Connectors](#)[Hardware](#)[S...](#)[Home](#)[About Abbatron](#)[Products](#)[Locate Distributor or Representative](#)[Contact Us](#)[Request Information](#)[Site Map](#)[Inventory Search](#)[Cross Reference](#)[UPS Tracking](#)

632 Arch Street, POB 726
 Meadville, PA 16335 USA
 814-724-6440
 Contact Webmaster
 © 2006

Miniature Binding Post

- Fluted post head is molded Lexan Polycarbonate with a gold plated brass insert
- The body is nickel plated brass
- Washers are molded nylon with a gold plated brass insert
- Mounts in panel hole as indicated in table
- Connect with .080" phone tip plug, spade lug, miniature banana plug, alligator wire(to #18)
- To connect circuit, wrap wire around solder turret to attach to solder lug below (Lug not supplied)
- Please refer to Table A(pg 26) for post rating information
- Posts shown here are available in standard red(-102) and black(-103) Other colors available from factory. Please add color to part number as suffix

[More information about binding posts](#)

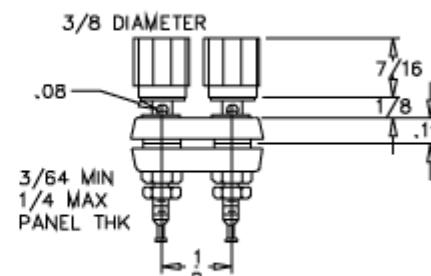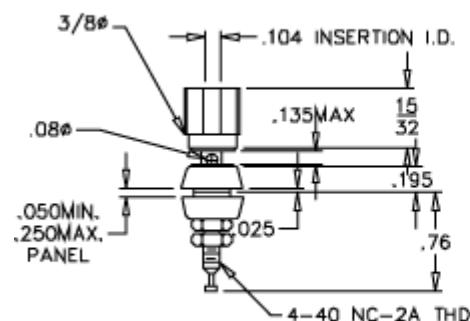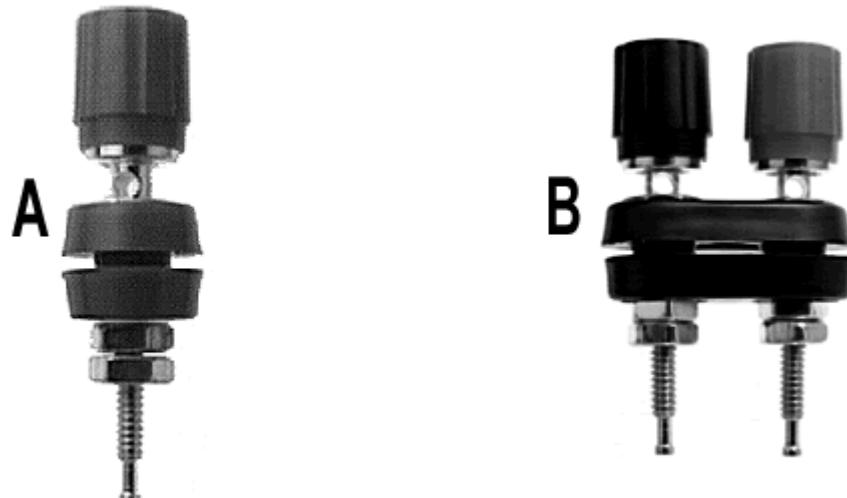

PART NO.	FIG.	MNTG HOLE	POST THREAD
3015	A		
3016BB			
3016RB	B	1/4	
3016RR			4-40

[home](#) | [about abbatron](#) | [products](#) | [locate distributor or representative](#) | [contact us](#) | [request information](#) | [site map](#)