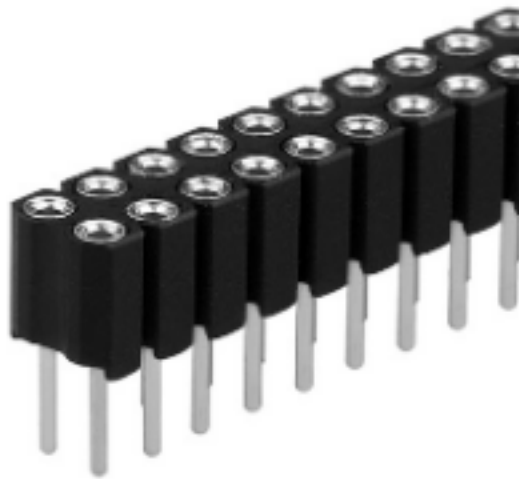


Data sheet Product BLY 2 82

[PRINT DATA SHEET](#)[RECOMMEND PAGE](#)

PCB connectors>Female headers
for □ 0.5 mm and up to 0.56 mm Ø

Features

pitch:	2.00 mm
no. of contacts:	82
contact material:	CuZn-alloy
contact sleeve:	tin-plated
surface contact / contact sleeve:	Ni+4...6µm Sn
contact spring:	gold-plated
inner contact spring material:	CuBe-alloy
inner contact spring surface:	Ni+0,25µm Au
type internal spring:	6-fingers
plugability for circuit points:	□0,45...0,5mm - Ø0,4...0,56mm
insert depth:	2.5...3.8mm
insertion / drawing force:	1.3N/0.3N
shock resistance:	50 g
volume resistance:	≤10 mΩ
vibration resistance max.:	15 g
capacity between two adjacent contacts:	≤0,7 pF
nominal current:	2.5 A
nominal voltage:	100 V DC
test voltage:	500 V
insulating body material:	PA 4.6. GF
temperature range:	-40°C... +163°C (260°C/10 s)
class of inflammability:	UL 94 V-0
version:	standard
specific insulation resistance:	>10 ⁷ Ω·m
connection type:	THT (soldering)
reflow solderable:	yes

Technical Drawing

