

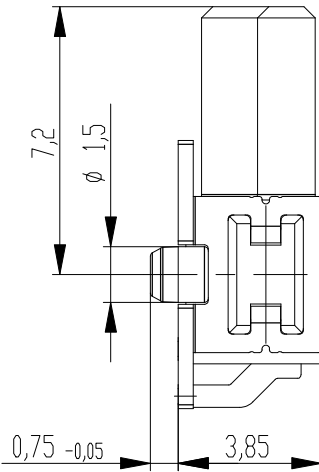
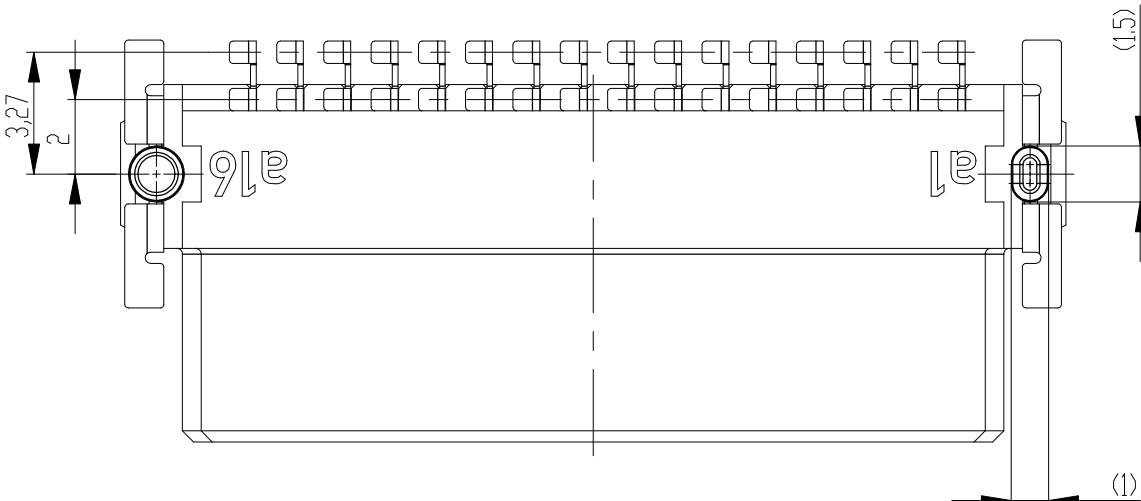
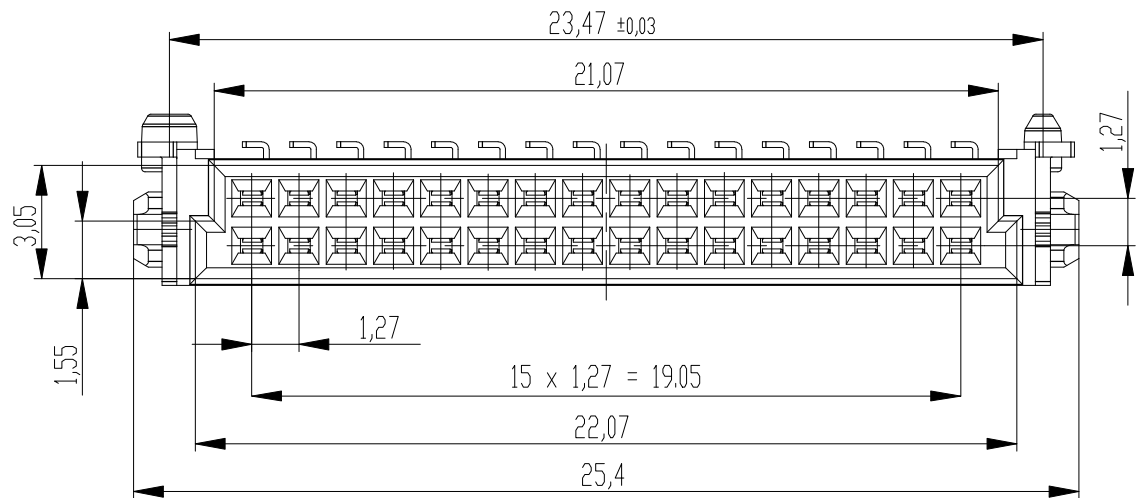
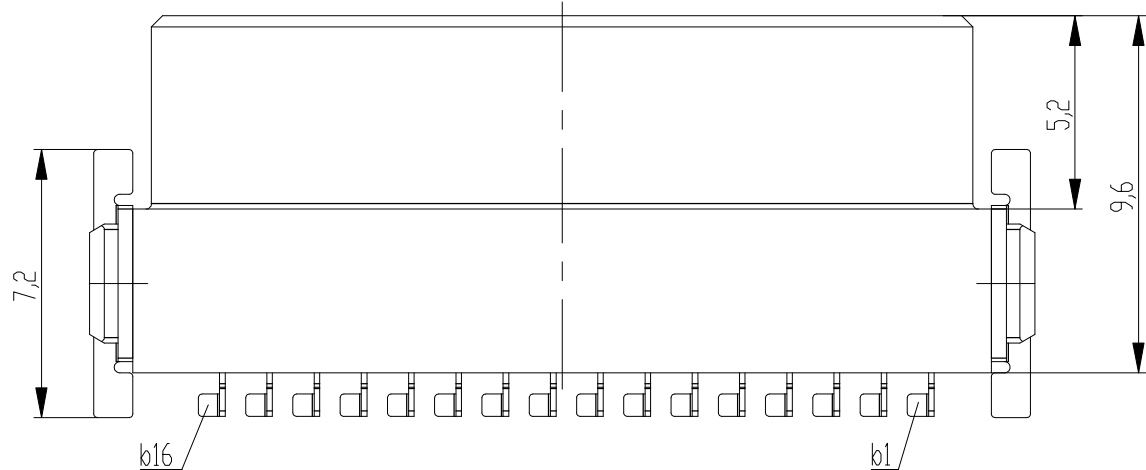
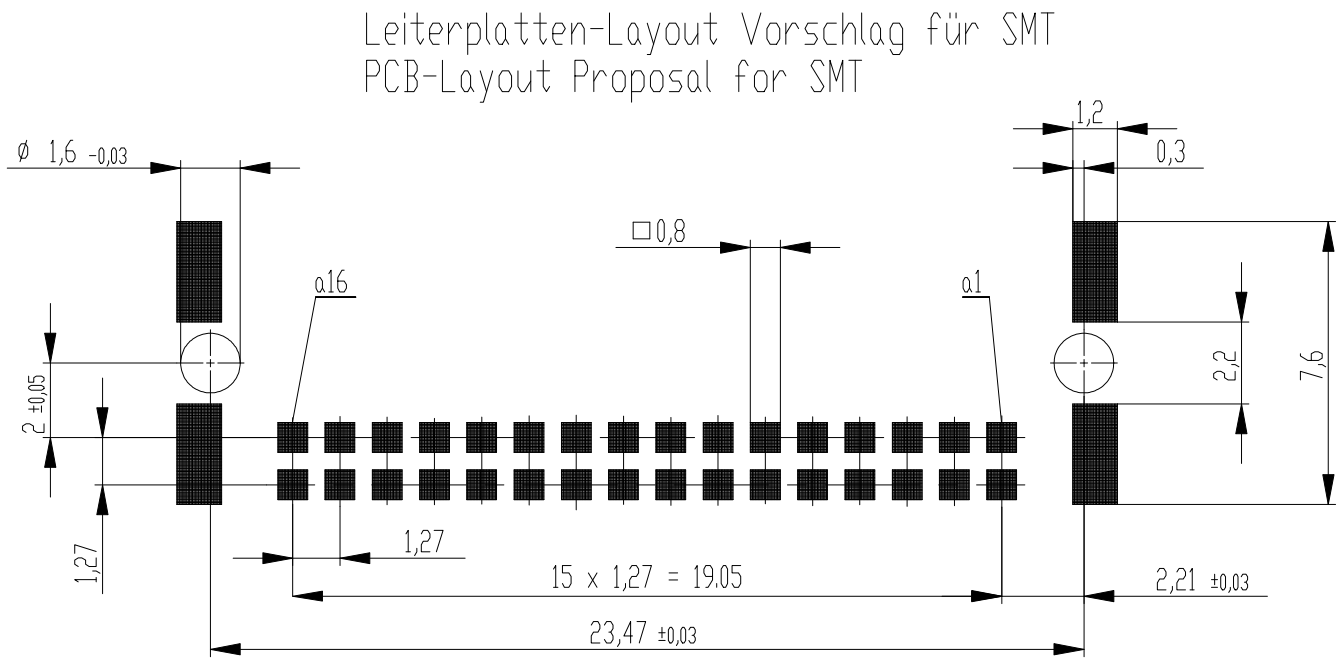


Alle Rechte vorbehalten. Nachdruck, Vervielfältigung und Verbreitung, auch auszugsweise, ist ohne schriftliche Genehmigung der SMC-Q GmbH. Die Rechte für den Fall der Patent-, Gebrauchsmuster- oder Geschmackschutzverletzung vorbehalten. The reproduction, distribution and utilization of this document as well as the communication of its contents to third parties is expressly prohibited without the prior written permission of SMC-Q GmbH. In case of any deviation the English version shall prevail.

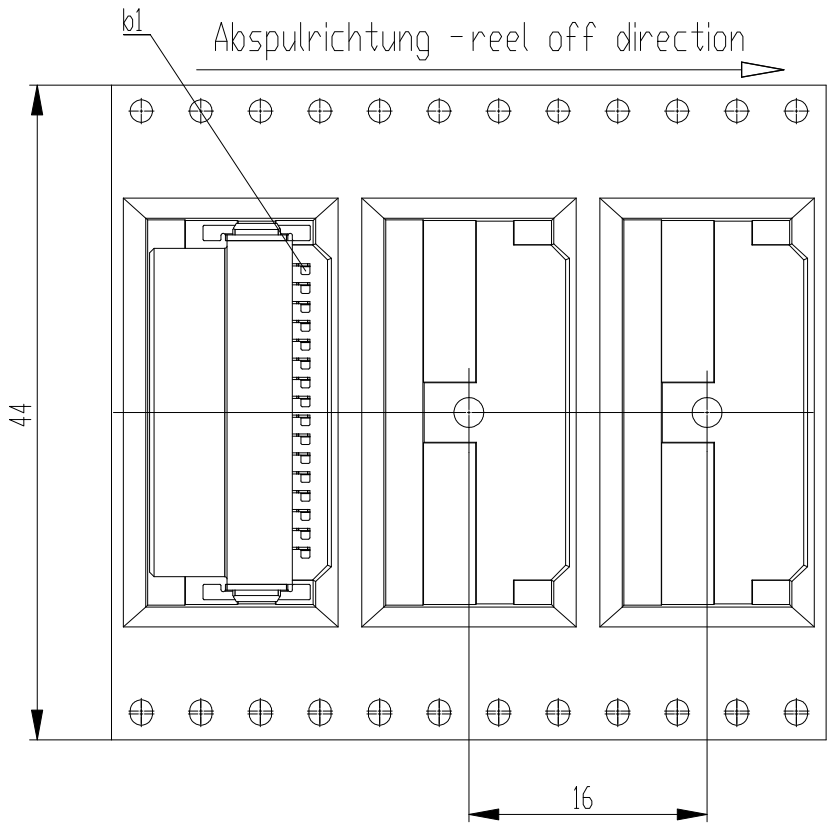

Verpackt im Gurt in Anlehnung an DIN IEC 60286-3
tape on reel packaging according to DIN IEC 60286-3
Verpackungseinheit: 560 Stück
packaging unit: 560 pcs

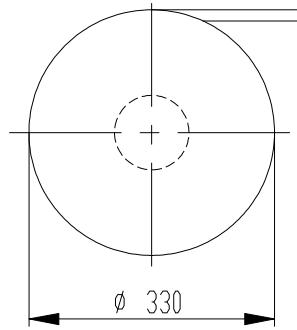

Anforderungsstufe 1
performance level 1

Kontaktbereich vergoldet
mating area gold plating

Anschlussbereich verzinkt 4-6 μ m
terminal area 4-6 μ m tin plating

Koplanarität der Anschlüsse $\leq 0,1$ mm
coplanarity area of termination $\leq 0,1$ mm

BA7-03 - Standard Bauhöhe

type7-03 - standard assembly height

Dimension no.	Tolerances Dim. for Information ISO 8015	All Dimensions in mm	Scale Material	5:1
Customer drawing: THIS DRAWING IS A CONTROLLED DOCUMENT.	Subject to modification without prior notice. Drawing will not be updated.		ERNI-Federl. SMC-Q 32-SMD-BA7-03 Female SMC-Q 32-SMD-type7-03	
c Index	07.02.2020 Date	TE Connectivity		1 A2
		Class	SMCQ	