

## Cable sleeve - CES-SRG-BK-9 - 0801622

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Small, slotted cable sleeves suitable for cables with a diameter of 8 ... 9 mm, material: NBR

### Product Description

Slotted sleeves for accommodating pre-assembled cables and lines with a diameter of 8 ... 9 mm, can be used in CES sealing frames. When fitted, the sleeves also ensure strain relief according to DIN EN 50262.

RoHS

### Key Commercial Data

|                                      |                                                                                                         |
|--------------------------------------|---------------------------------------------------------------------------------------------------------|
| Packing unit                         | 1 STK                                                                                                   |
| Minimum order quantity               | 10 STK                                                                                                  |
| GTIN                                 | <br>4 046356 674683 |
| GTIN                                 | 4046356674683                                                                                           |
| Weight per Piece (excluding packing) | 6.000 g                                                                                                 |
| Custom tariff number                 | 40169300                                                                                                |
| Country of origin                    | Taiwan                                                                                                  |

### Technical data

#### Dimensions

|                         |                  |
|-------------------------|------------------|
| External cable diameter | 1x 8 mm ... 9 mm |
| Length                  | 29.5 mm          |
| Width                   | 19.5 mm          |
| Height                  | 17 mm            |

#### Ambient conditions

|                                 |                                          |
|---------------------------------|------------------------------------------|
| Degree of protection            | IP54 (Observe the assembly instructions) |
| Ambient temperature (operation) | -40 °C ... 125 °C (static)               |

## Cable sleeve - CES-SRG-BK-9 - 0801622

### Technical data

#### General


|                           |                                                                                                                                                                                                                  |
|---------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Product description       | Slotted sleeves for accommodating pre-assembled cables and lines with a diameter of 8 ... 9 mm, can be used in CES sealing frames. When fitted, the sleeves also ensure strain relief according to DIN EN 50262. |
| No. of conductors         | 1                                                                                                                                                                                                                |
| Material                  | NBR                                                                                                                                                                                                              |
| Color                     | black                                                                                                                                                                                                            |
| Installation instructions | IP54: for vertical sealing frame mounting/for horizontal sealing frame mounting (downward cable outlet direction).                                                                                               |

#### Environmental Product Compliance

|            |                                                         |
|------------|---------------------------------------------------------|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
|            | No hazardous substances above threshold values          |

### Drawings

Dimensional drawing

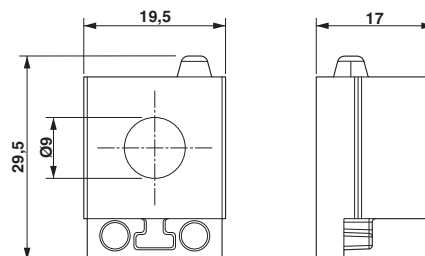

Dimensional drawing

### Classifications

#### eCl@ss

|            |          |
|------------|----------|
| eCl@ss 4.0 | 27081002 |
| eCl@ss 4.1 | 27081002 |
| eCl@ss 5.0 | 27081002 |
| eCl@ss 5.1 | 27081002 |
| eCl@ss 6.0 | 27081002 |
| eCl@ss 7.0 | 27081002 |
| eCl@ss 8.0 | 27069220 |
| eCl@ss 9.0 | 27144425 |

#### ETIM

|          |          |
|----------|----------|
| ETIM 3.0 | EC000879 |
|----------|----------|

## Cable sleeve - CES-SRG-BK-9 - 0801622

### Classifications

#### ETIM

|          |          |
|----------|----------|
| ETIM 4.0 | EC000451 |
| ETIM 5.0 | EC000451 |
| ETIM 6.0 | EC000451 |

#### UNSPSC

|               |          |
|---------------|----------|
| UNSPSC 6.01   | 30212109 |
| UNSPSC 7.0901 | 39121708 |
| UNSPSC 11     | 39121708 |
| UNSPSC 12.01  | 39121708 |
| UNSPSC 13.2   | 39121448 |

### Approvals

#### Approvals

---

Approvals

GL

---

Ex Approvals

---

#### Approval details

|    |                                                                                     |                                                                                                                                 |            |
|----|-------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|------------|
| GL |  | <a href="http://www.gl-group.com/newbuilding/approvals/index.html">http://www.gl-group.com/newbuilding/approvals/index.html</a> | 1391415 HH |
|----|-------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|------------|