

BPSD00080750101M00

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




MP ?

Unshielded Type

- Series Pdf
- RoHSREACHCoC

Product detail	
L(mm) ±	7.8±0.3
W(mm) ±	7.0±0.3
T(mm) ±	5.0±0.3
Inductance(uH)	100
Tolerance(±%)	20
Test Frequency	1 kHz,1 V
RDC(Ω)Max	0.43
Isat(A)	0.72
Operating Temperature	− 40°C~ 105°C(Including self - temperature rise)

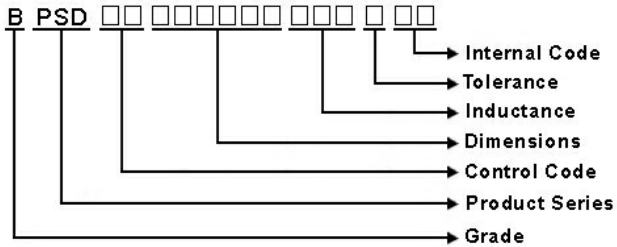

Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Passives/Antennas
- LAN Transformer
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisín](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisín. All rights reserved.