



Connectors > Connector Accessories > Connector Seals & Cavity Plugs



Connector Seal & Plug Type: **Sealing Plug**

Cavity Diameter: **1.55 mm [.061 in]**

Primary Product Color: **Violet**

Primary Product Material: **PA GF**

Features

Product Type Features

|                            |              |
|----------------------------|--------------|
| Connector Seal & Plug Type | Sealing Plug |
|----------------------------|--------------|

Body Features

|                          |        |
|--------------------------|--------|
| Primary Product Color    | Violet |
| Primary Product Material | PA GF  |

Dimensions

|                 |                  |
|-----------------|------------------|
| Wire Size       | 18 AWG           |
| Cavity Diameter | 1.55 mm[.061 in] |

Packaging Features

|                  |             |
|------------------|-------------|
| Packaging Method | Loose Piece |
|------------------|-------------|

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

|                                               |                                         |
|-----------------------------------------------|-----------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                               |
| EU ELV Directive 2000/53/EC                   | Compliant                               |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold |



|                                        |                                                                                                                               |
|----------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| EU REACH Regulation (EC) No. 1907/2006 | Current ECHA Candidate List: JAN 2025 (247)<br>Candidate List Declared Against: JAN 2025 (247)<br>Does not contain REACH SVHC |
| Halogen Content                        | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free                                           |
| Solder Process Capability              | Not reviewed for solder process capability                                                                                    |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 3-2112780-1  
18POS, MIXED,REC HSG,ASSY, SEALED

TE Part # 5-2112780-0  
TWO WHEELER

TE Part # 1-2208720-1  
105POS,MCON 1.2 CB,REC HSG, ASSY,SLD


Also in the Series | MCON 1.2mm

Automotive Connector Caps & Covers (15)


Automotive Connector Locks & Position Assurance(9)

Automotive Housings(325)

Automotive Seals & Cavity Plugs(18)

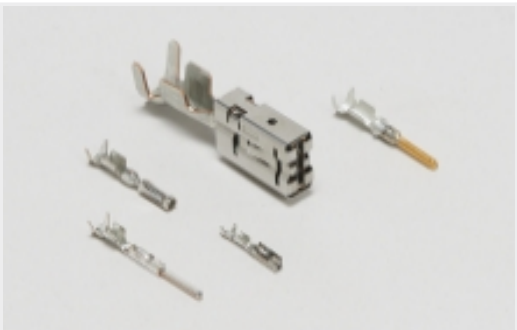

Automotive Terminals(90)

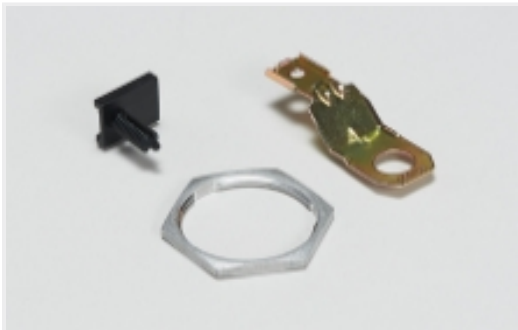

Other Automotive Connector Accessories(12)

Customers Also Bought



TE Part #CAT-AM705-T273  
AMP MCP, RECEPTACLE AND TAB



TE Part #1456968-1  
CONTACT,FEMALE, 0.64, 20 TO 22 AWG, AG



TE Part #1670144-1  
MCON 1.2 CB REC SRC SN



TE Part #1670789-1  
2. LOCK



 
TE Part #1-2112780-9  
18POS, MIXED,REC HSG,ASSY, SEALED




TE Part #2301462-1  
30POS,HYBRID,REC HSG ASSY,SLD, COD A



TE Part #2338360-1  
2P ECONOSEAL RECEPTACLE ASSY



TE Part #2112758-1  
COVER

 

TE Part #2338363-1  
2P ECONOSEAL RECEPTACLE DBL

Documents

Product Drawings  
BLIND PLUG,MCON 1.2 CB  
English

CAD Files  
3D PDF  
3D  
Customer View Model  
ENG\_CVM\_CVM\_2286476-1\_A.2d\_dxf.zip



English

Customer View Model

[ENG\\_CVM\\_CVM\\_2286476-1\\_A.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_2286476-1\\_A.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

Data sheet

English

[product-2286476-1\\_datasheet](#)

English