


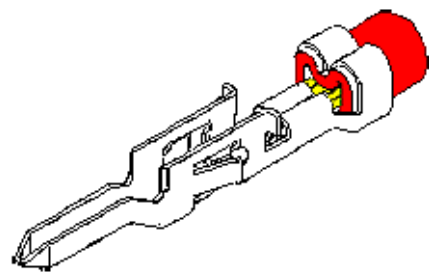

Part Number : [444781111](#)
Product Description : Mini-Fit HCS Crimp
Terminal, 20-18 AWG, Reel, Copper (Cu) Alloy,
Tin (Sn)
Series Number : 44478
Status : Active
Product Category : Crimp Terminals



Documents & Resources

Drawings
[444781111_sd.pdf](#)
[PK-44478-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Crimp Terminals
Series	44478
Description	Mini-Fit HCS Crimp Terminal, 20-18 AWG, Reel, Copper (Cu) Alloy, Tin (Sn)
Application	Power
Comments	High Current
Product Name	Mini-Fit
UPC	800755527452

Electrical

Current - Maximum per Contact	11.0A
-------------------------------	-------

Physical

Gender	Male
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.133/g
Packaging Type	Reel
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	1.30-3.10mm
Wire Size (AWG)	18, 20
Wire Size mm ²	N/A

Application Tooling

Global

Description	Part Number
-------------	-------------

Extraction Tool for Mini-Fit Jr. Terminals	<u>11030044</u>
PremiumGrade Hand Crimp Tool for Mini-Fit Jr. Male and Female Terminals, 24-18 AWG	<u>638190901</u>
FineAdjust Applicator for 20-18 AWG and 24-18 AWG Wires with Insulation Diameter 1.90-2.30mm	<u>639015600</u>
FineAdjust Applicator for Insulation OD 1.40-1.70mm - 24-18 AWG	<u>639023900</u>
FineAdjust Applicator for Insulation OD 2.50-2.95mm Optimized for 18 AWG Only	<u>639024800</u>
FineAdjust Applicator for Insulation OD 2.30-2.60mm - 24-18 AWG	<u>639024900</u>
FineAdjust Applicator for Insulation OD 2.50-2.95mm, 24-18 AWG	<u>639047800</u>
FineAdjust Applicator for Insulation OD 1.65-2.05mm, 24-18 AWG	<u>639048000</u>
T2 Terminator for Insulation OD 1.90-2.30mm - 24-18 AWG	<u>639115600</u>
T2 Terminator for insulation OD 1.40-1.70mm - 24-18 AWG	<u>639123900</u>
T2 Terminator for insulation OD 2.50-2.95mm optimized for 18 AWG only	<u>639124800</u>
T2 Terminator for insulation OD 2.30-2.60mm - 24-18 AWG	<u>639124900</u>
T2 Terminator for Mini-Fit Crimp Terminals, 24-18 AWG with Large Insulation ODs	<u>639147800</u>
T2 Terminator for Mini-Fit Crimp Terminals, 24-18 AWG with Smaller Insulation ODs	<u>639148000</u>

This document was generated on Mar 16, 2025