

BPSF00070732100M00

Search by :

Part Number

Characteristics

Cross reference




MP ?

Closed Magnetic Circuit Type

Series Pdf

Product detail		
L (mm) ±		7±0.2
W(mm) ±		7±0.2
T (mm) ±		3.2±0.2
Inductance(uH)		10
Tolerance(±%)		20
Test Frequency		0.5V 1kHz
RDC(ohm)		0.053
RDC Tolerance(±%)		20
Isat(A)		1.4

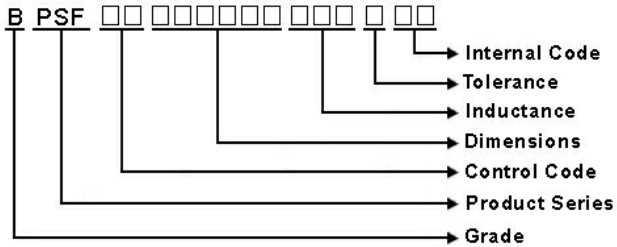

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

- Media Center
- New Products

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.