


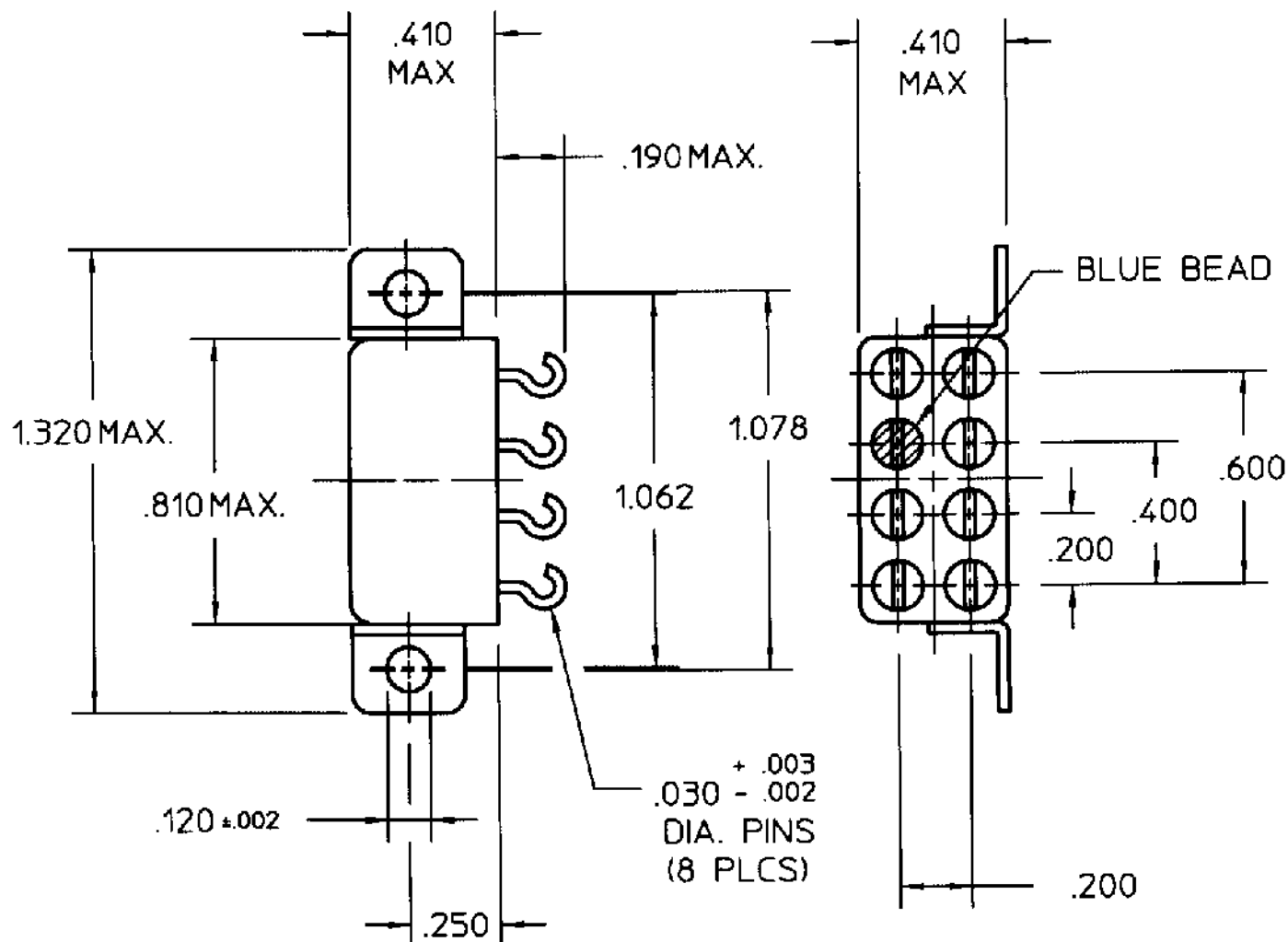

COIL: @ +25° C	
RESISTANCE	160 OHMS ± 10%
NOMINAL VOLTAGE	12.0 VDC
MUST OPERATE	6.4 VDC
MUST RELEASE	4.0 VDC MAX 0.7 VDC MIN

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

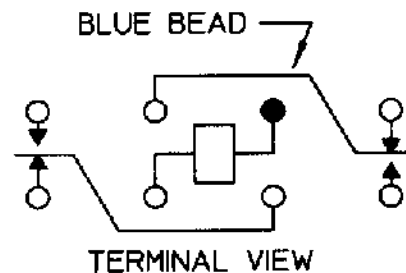

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/20/98 CK. 11/20/98

 COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/6-114M

TYPE "HFW" RELAY

HFV1131G01M