


7-1377174-9 Product Details

 Share Print Email

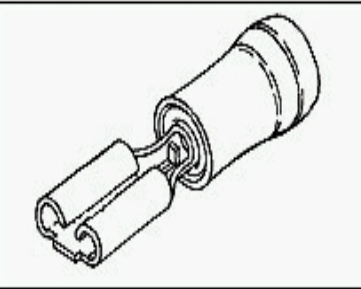

7-1377174-9

TE Internal Number: 7-1377174-9

 Active

Quick Disconnect Receptacles - Insulated

 Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Proprietary Name = PIDG FASTON
- Receptacle Style = Straight
- Wire Range = 0.30-1.50² [22-15] mm [AWG]
- Mating Area Interface Dimensions = 2.79 x 0.30 mm
- Insulation Diameter = 3.56 [.140] Max. mm [in]

[View all Features](#)

Quick Links

-  Pricing & Availability
-  Search for Tooling
-  Product Feature Selector
-  Contact Us About This Product

 [Add to My Part List](#)

 [Request Sample](#)

 [Find Similar Products](#)

 [Buy Product](#)

Documentation & Additional Information	
Product Drawings: SMALL PACK (PDF, English) Catalog Pages/Data Sheets: - None Available Product Specifications: - None Available Application Specifications: - None Available Instruction Sheets: - None Available CAD Files: - None Available	Additional Information: Product Line Information Related Products: Tooling
List all Documents	

Product Features (Please use the Product Drawing for all design activity)	
Product Type Features: Receptacle Style = Straight Insertion Force = Normal Finish = Tin Dimple Type = Dimple without wire stop - Insulation Support = Insulation Support - Color = Red Electrical Characteristics: - Voltage (VAC) = 300 Dimensions: Mating Area Interface Dimensions (mm [in]) = 2.79 x 0.30 [.110 x .012] Insulation Diameter (mm [in]) = 3.56 [.140] Max. Body Features: Fully Insulated = No Wire Range (mm [AWG]) = 0.30-1.50² [22-15] - Material = Brass - Insulation Sleeve Material = Nylon	Industry Standards: RoHS/ELV Compliance = RoHS compliant, ELV compliant Lead Free Solder Processes = Not relevant for lead free process - RoHS/ELV Compliance History = Always was RoHS compliant Packaging Features: Packaging Method = Loose Piece - Packaging Quantity = 50/Plastic Box; 20 Boxes/Carton Other: Proprietary Name = PIDG FASTON - Brand = AMP - Comment = Bulk number 165563-1.