

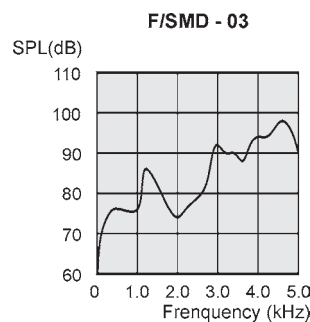


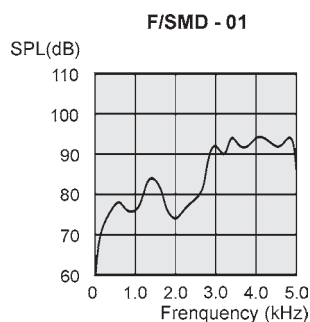

SMT - Buzzer

F/SMD-01A

F/SMD-03A

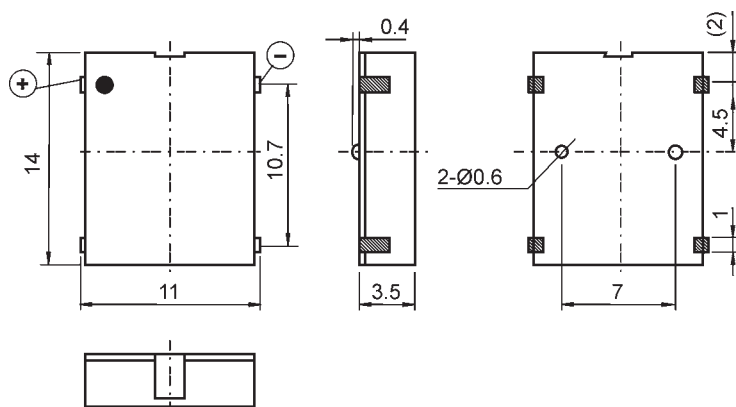

Typischer Frequenzgang
Typical frequency response

Technische Daten / technical data:	F/SMD-01A	F/SMD-03A
Betriebsspannungsbereich / operating voltage range (V)	1,2...1,7	2...4,5
Nennspannung / rated voltage (V)	1,5	3
Nennstrom / rated current* (mA)	≤ 80	≤ 70
Lautstärke / sound pressure level (SPL) (dB/10 cm)	≥ 85	≥ 87
Resonanzfrequenz / resonant frequency (Hz)	3200	3200
Wicklungswiderstand / coil resistance (Ω)	9 ± 2	19 ± 2
Impedanz / impedance (Ω)	8,7	20
Betriebstemperatur / operating temperature (°C)	-40...+85	-40...+85
Lagertemperatur / storage temperature (°C)	-40...+90	-40...+90
Gewicht / weight (g)	1	1

* Wert bei angelegter Nennspannung (3200 Hz, 1/2 Tastverhältnis, Rechteck)
Value applying rated voltage (3200 Hz, 1/2 duty, square wave)