


## H2,5/19D BL

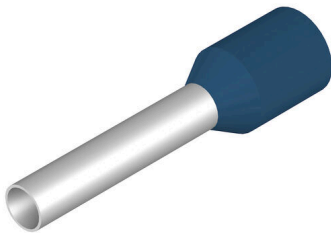

- supplied loose in polybag
- DIN colour code
- other colour code

### General ordering data

Version	Wire-end ferrule, Standard, 14 mm, 12 mm, blue
Order No.	<a href="#">9019170000</a>
Type	H2,5/19D BL
GTIN (EAN)	4008190178024
Qty.	500 items
Packaging	loose

## Technical data

### Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E499744

### Dimensions and weights

Net weight 0.18 g

### Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

### Technical data

Description of article	Wire end ferrule with plastic collar, blue	Version	Standard
------------------------	--	---------	----------

### Wire-end ferrules

Contact surface diameter (D1)	2.2 mm	Contact surface length (L2)	12 mm
Collar diameter (D2)	4.2 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	19.00 mm	Wire connection cross section AWG, max.	AWG 14
Metal sleeve thickness (S1)	0.15 mm	Military designation	T 20A 017 A
Stripping length	14 mm	Conductor cross-section	2.5 mm <sup>2</sup>
Colour code	DIN		

### Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

