




USB connection cable, A/M - B/M


AK-300102-018-E 4016032282624

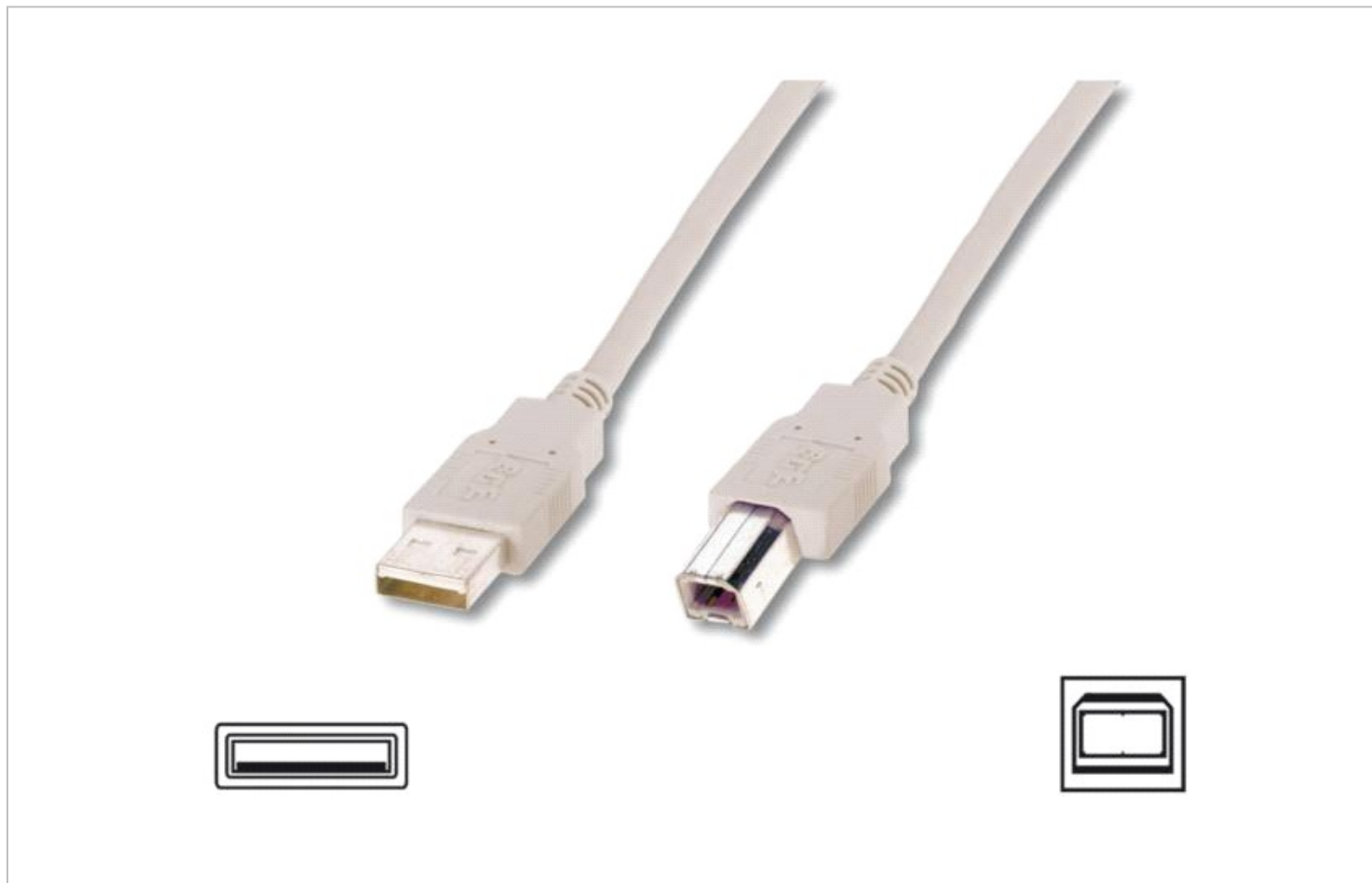

M/M, 1.8m, USB 2.0 suitable, UL, be

Allows a reliable and fast connection of external USB devices to the PC.

- Connector 1: USB A, plug
- Connector 2: USB B, plug
- USB compliance: USB 2.0
- UL certified: UL2725
- Hoods: molded
- Shielding: double shielding
- AWG: 28
- Wire material: CCS
- Connector surface: nickel-plated
- Ferrite filter: none
- Color cable: beige
- Color connector: beige
- Length: 1.8 m

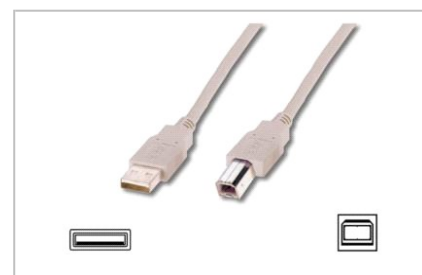



USB connection cable, A/M - B/M

AK-300102-018-E 4016032282624

→ Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	250	14,00	45,00	32,00	25,00	36000,00
Packaging Unit Inside	10	0,56	21,00	34,00	3,00	2142,00
Packaging Unit Single	1	0,06	1,00	16,00	19,00	304,00
Net single without Packaging	1	0,00	1,00	12,00	15,00	180,00

Country of origin: China

