


Technical data sheet

Article number:
318-43200

TA42-32/8

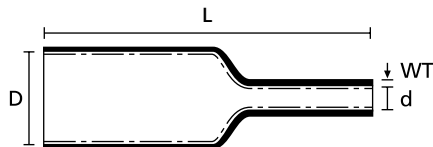

Product Group	Heat shrinkable tubing adhesive lined - 1.2 m lengths
Product Family	TA42 - thin wall, 4:1 shrink ratio
Material	Polyolefin, cross-linked (PO-X)
Colour	Black (BK)
Adhesive	Hot melt adhesive
Behaviour at Heat Shock	not cracking, not dripping, not fluid
Dielectric Strength [Test method]	20 kV/mm [ASTM D876]
Elongation at break (min.) [Test method]	350 % [ASTM D638]
Flammability	UL 224 VW-1
Heat Shock Test	4h/250°C
Min. Shrink Temperature - °C	+110 °C
Operating Temperature	-55 °C to +125 °C
Package Content	10 pcs.
Package Content packed in	pcs.
Recov. Ø d max.	8.0 mm
Shrink Ratio	4:1
Specifications	ANSI/UL 224
Supplied Ø D min.	32.0 mm
Tensile Strength [Test method]	15 MPa [ASTM D638]
UL-File Number	E198023
Wall (WT)	2.50 mm

RoHS

