

ORDERING CODE:

KNT	-	XXX	-	PX
IS THE SERIES		INSERT YOUR LENGTH OF SERIES KT		INSERT YOUR LED CODE: P...

Type	Length
KT-02	L = 2 mm
KT-04	L = 4 mm
KT-054	L = 5,4 mm
KT-06	L = 6 mm
KT-075	L = 7,5 mm
KT-085	L = 8,5 mm
KT-10	L = 10 mm
KT-13	L = 13 mm
KT-15	L = 15 mm
KT-17	L = 17 mm
KT-20	L = 20 mm
KT-25	L = 25 mm
KT-30	L = 30 mm
KT-37	L = 37,9 mm
KT-40	L = 40 mm
KT-45	L = 45 mm
KT-47	L = 47,5 mm
KT-50	L = 50 mm
Your length	L =

OPTIONS AVAILABLE


- Other standard lengths - from 1 to 50 mm
- Right angle
- Different shapes and lengths
- Low current (2 mA)
- Led from 10mcd to 3.000mcd
- 5V & 12V integrated resistor
- White LEDs
- Ultrabright-Infrared & Phototransistor
- Blinking LEDs
- Bicolor 3 Leads
- Special LEDs on request

HOLDER				
Type	Temperat. Range	Deflected Temp.	Flamability	Material
KNT	-60°C + 125°C	152°C	UL-94-V0	PA 6.6

LED					
IF 20mA					
Code	Size	Emited Color	mcd (TYP)	V (TYP)	Peak (nm)
P1	Ø3mm	Red	100	2.0	635
P2	Ø3mm	Green	100	2.2	568
P3	Ø3mm	Yellow	90	2.1	585
P4	Ø3mm	Bi-color red/green	30	2.2	635/568
P5	Ø3mm	Blue	60	5.1	430


Dimensions in mm (typical)

KT

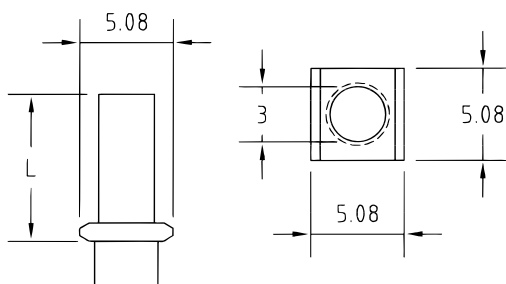


Dimensions in mm (typical)

KNT

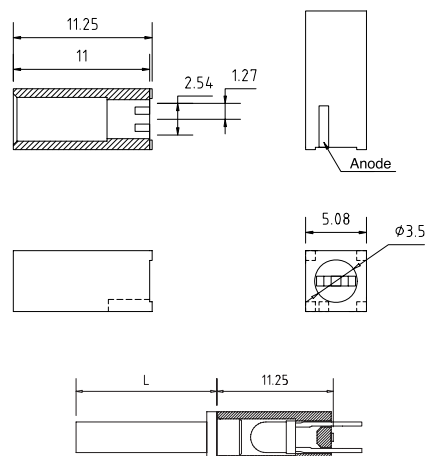


Dimensions in mm (typical)

333 Series

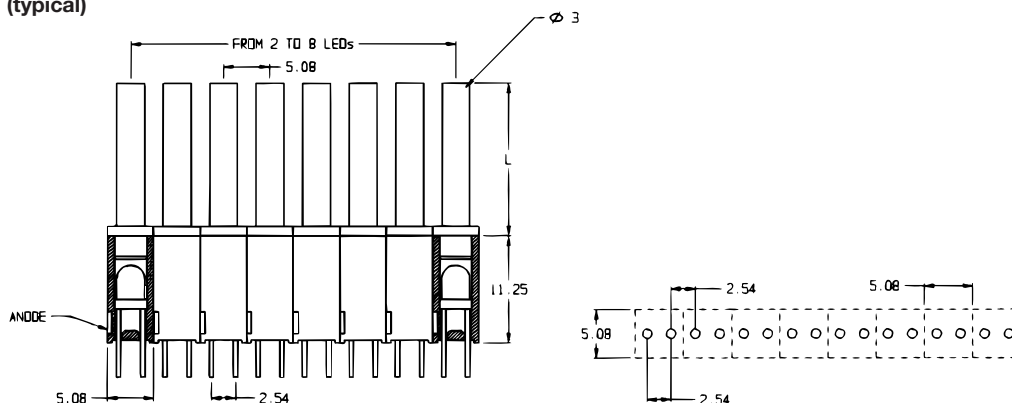

Dimensions in mm (typical)

111 Series

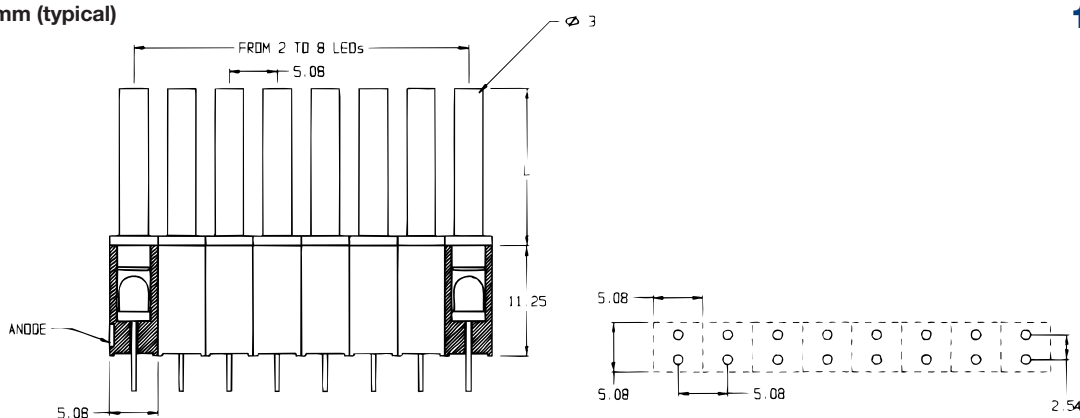

ORDERING CODE:

KNT	-	X	-	XXX	-	PX	-	XXX
IS THE SERIES		NUMBER OF LEDS		INSERT YOUR LENGTH * OF SERIES KT		INSERT YOUR LED CODE: P...		TYPE OF MOUNTING: • 333 • 111

MULTICOLOURED: INDICATE COLOURS FROM LEFT TO RIGHT IN P... RIGHT ANGLE: INDICATE **RA** (ONLY IN VERSION 333)

Number Leds	Length L (series KT)	*	Number Leds	Length L (series KT)
2	- 2 ÷ 50 mm		6	- 2 ÷ 15 mm
3	- 2 ÷ 50 mm		7	- 2 ÷ 15 mm
4	- 2 ÷ 15 mm		8	- 2 ÷ 15 mm
5	- 2 ÷ 15 mm		• SPECIAL LENGTH ON REQUEST	

One of many applications

