



Shrinkable markers "Ladder Style", thermal transfer

TULT DS – 3:1 Military and Electronics "Ladder Style"


TULT DS is a UL recognised 3:1 heat shrink marker material pre-cut and formatted into a convenient "ladder" system. This pre-cut format not only allows printing on both sides of the marker but the user can also easily choose and pick each required marker. TULT's polyolefin compound has good mechanical strength and resistance to organic solvents and chemicals. The surface of the tubing has been especially prepared so that print performance is excellent at all times using HellermannTyton's printer range.

Features and benefits

- Shrink ratio 3:1
- 50 mm, 25 mm and 16 mm pre-cut marker options as standard, other lengths available on request
- Available in white or yellow
- Good mechanical strength and resistance to organic solvents and chemicals
- Highly flexible
- Delivery in convenient storage boxes



One Step to the Web!

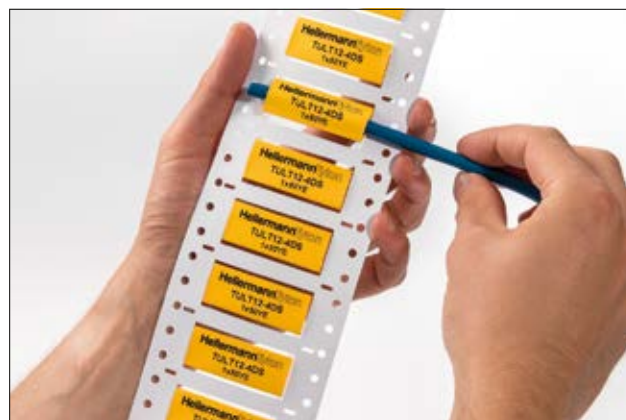

Shrinkable markers TULT DS for military and electronics industry.

MATERIAL	Polyolefin, cross-linked (PO-X)
Operating Temperature	-55 °C to +135 °C
Min. Shrink Temperature	+90 °C
Shrink Ratio	3:1
Recommended Ribbon Type	TTDTHOUT
Thermal Transfer Printer	TT430, TT4030, TrakMark DS

RoHS



For size matrix please refer to page 439.

TYPE	Supplied Ø D min.	Recov. Ø d max.	Length (L)	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT2.4-0.8DS-2x25WH	2.4	0.8	25.0	0.73	2,000 pcs.	White (WH)	553-71002
TULT2.4-0.8DS-2x25YE	2.4	0.8	25.0	0.73	2,000 pcs.	Yellow (YE)	553-71003
TULT2.4-0.8DS-1x50WH	2.4	0.8	50.0	0.73	1,000 pcs.	White (WH)	553-71000
TULT2.4-0.8DS-1x50YE	2.4	0.8	50.0	0.73	1,000 pcs.	Yellow (YE)	553-71001
TULT3-1DS-2x25WH	3.0	1.0	25.0	0.60	2,000 pcs.	White (WH)	553-71008
TULT3-1DS-2x25YE	3.0	1.0	25.0	0.60	2,000 pcs.	Yellow (YE)	553-71009
TULT3-1DS-1x50WH	3.0	1.0	50.0	0.60	1,000 pcs.	White (WH)	553-71006
TULT3-1DS-1x50YE	3.0	1.0	50.0	0.60	1,000 pcs.	Yellow (YE)	553-71007

 
All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



For product specific approvals and specifications please refer to the Appendix.

Shrinkable markers "Ladder Style", thermal transfer

TULT DS – 3:1 Military and Electronics "Ladder Style"



TYPE	Supplied Ø D min.	Recov. Ø d max.	Length (L)	Wall (WT)	Pack Cont.	Colour	Article-No.
TULT4.8-1.6DS-2x25WH	4.8	1.6	25.0	0.66	2,000 pcs.	White (WH)	553-71014
TULT4.8-1.6DS-2x25YE	4.8	1.6	25.0	0.66	2,000 pcs.	Yellow (YE)	553-71015
TULT4.8-1.6DS-1x50WH	4.8	1.6	50.0	0.66	1,000 pcs.	White (WH)	553-71012
TULT4.8-1.6DS-1x50YE	4.8	1.6	50.0	0.66	1,000 pcs.	Yellow (YE)	553-71013
TULT6-2DS-2x25WH	6.0	2.0	25.0	0.69	2,000 pcs.	White (WH)	553-71020
TULT6-2DS-2x25YE	6.0	2.0	25.0	0.69	2,000 pcs.	Yellow (YE)	553-71021
TULT6-2DS-1x50WH	6.0	2.0	50.0	0.69	1,000 pcs.	White (WH)	553-71018
TULT6-2DS-1x50YE	6.0	2.0	50.0	0.69	1,000 pcs.	Yellow (YE)	553-71019
TULT9-3DS-2x25WH	9.0	3.0	25.0	0.79	1,000 pcs.	White (WH)	553-71026
TULT9-3DS-2x25YE	9.0	3.0	25.0	0.79	1,000 pcs.	Yellow (YE)	553-71027
TULT9-3DS-1x50WH	9.0	3.0	50.0	0.79	500 pcs.	White (WH)	553-71024
TULT9-3DS-1x50YE	9.0	3.0	50.0	0.79	500 pcs.	Yellow (YE)	553-71025
TULT12-4DS-2x25WH	12.0	4.0	25.0	0.84	1,000 pcs.	White (WH)	553-71032
TULT12-4DS-2x25YE	12.0	4.0	25.0	0.84	1,000 pcs.	Yellow (YE)	553-71033
TULT12-4DS-1x50WH	12.0	4.0	50.0	0.84	500 pcs.	White (WH)	553-71030
TULT12-4DS-1x50YE	12.0	4.0	50.0	0.84	500 pcs.	Yellow (YE)	553-71031
TULT18-6DS-2x25WH	18.0	6.0	25.0	1.00	1,000 pcs.	White (WH)	553-71038
TULT18-6DS-2x25YE	18.0	6.0	25.0	1.00	1,000 pcs.	Yellow (YE)	553-71039
TULT18-6DS-1x50WH	18.0	6.0	50.0	1.00	500 pcs.	White (WH)	553-71036
TULT18-6DS-1x50YE	18.0	6.0	50.0	1.00	500 pcs.	Yellow (YE)	553-71037
TULT24-8DS-2x25WH	24.0	8.0	25.0	1.20	500 pcs.	White (WH)	553-71044
TULT24-8DS-2x25YE	24.0	8.0	25.0	1.20	500 pcs.	Yellow (YE)	553-71045
TULT24-8DS-1x50WH	24.0	8.0	50.0	1.20	250 pcs.	White (WH)	553-71042
TULT24-8DS-1x50YE	24.0	8.0	50.0	1.20	250 pcs.	Yellow (YE)	553-71043
TULT39-13DS-2x25WH	39.0	13.0	25.0	1.25	500 pcs.	White (WH)	553-71050
TULT39-13DS-2x25YE	39.0	13.0	25.0	1.25	500 pcs.	Yellow (YE)	553-71051
TULT39-13DS-1x50WH	39.0	13.0	50.0	1.25	250 pcs.	White (WH)	553-71048
TULT39-13DS-1x50YE	39.0	13.0	50.0	1.25	250 pcs.	Yellow (YE)	553-71049

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.



For product specific approvals and specifications please refer to the Appendix.