

Data Sheet | Item Number: 281-485

Jumper; 5-way; insulated; gray

<https://www.wago.com/281-485>



Color: ■ gray

Similar to illustration

Physical data

Width	28.3 mm / 1.114 inches
Height	5 mm / 0.197 inches
Depth	20.6 mm / 0.811 inches
Jumper assignment	1-2-3-4-5

Material data

Note (material data)	Information on material specifications can be found here
Color	gray
Material group	I
Insulation material (main housing)	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.019 MJ
Weight	3.9 g

Commercial data

PU (SPU)	100 (25) pcs
Packaging type	Box
Country of origin	DE
GTIN	4044918524278
Customs tariff number	85366990990



Product Classification

UNSPSC	39121421
eCl@ss 10.0	27-14-11-40
eCl@ss 9.0	27-14-11-40
ETIM 9.0	EC000489
ETIM 10.0	EC000489
ECCN	NO US CLASSIFICATION

Environmental Product Compliance

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 281-485	↓

Documentation

Bid Text			
281-485	19.02.2019	xml 2.54 KB	↓
281-485	28.04.2017	doc 24.00 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 281-485	↓

CAE data	
EPLAN Data Portal 281-485	↓
WSCAD Universe 281-485	↓
ZUKEN Portal 281-485	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Tool

1.1.1.1 Operating tool




Item No.: 281-440

Operating tool; made of insulating material; 5-way

Installation Notes

Commoning

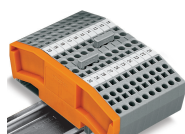


Commoning using comb-style jumper bars.
Push comb-style jumper bars down until fully inserted.

Commoning



4-conductor through terminal blocks, angled type, formation of groups with 3-way, comb-style jumper bars

Commoning

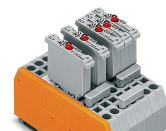

Carrier terminal blocks with component plugs, alternate comb-style jumper bars, 3-way comb-style jumper bar

Commoning



Commoning front-entry disconnect terminal blocks via comb-style jumper bar using a 10-pole operating tool