




+ WIRE AND CABLE
HOOK UP WIRE

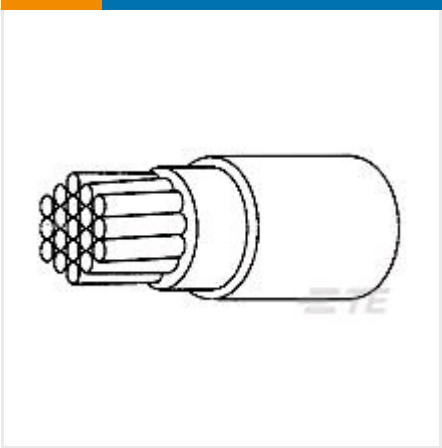

✓ Active

TE CONNECTIVITY (TE)
100G0111-1.50-2
Raychem | SP

100G0111-1.50-2
TE Internal Number: 4516513001
Alias ID: 7-1193391-0

EU RoHS Compliant
EU ELV Compliant
Cable Type Spec 100G
Voltage Rating (V) 750/1300
Insulation Material Halogen-Free Polymer
Conductor Material Tin-Plated Copper
Wire Size (AWG) 15

↓ PRODUCT DRAWING
English

DOCUMENTATION

Product Drawings
Customer Drawing
PDF
English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.
Please Note: Use the Product Drawing for all design activity.

Product Type Features

Cable Type Spec 100G
Cable Style Primary
Product Classification Cable - Spec 99 & 100
Product Type Cable

Configuration Features

Number of Strands 37
Number of Conductors 1

Electrical Characteristics

Voltage Rating (V) 750/1300

Body Features

Insulation Material Halogen-Free Polymer
Conductor Material Tin-Plated Copper
Wire Color Red

Dimensions

Strand Size (AWG) 37
Wire Size (AWG) 15
Wire Size (mm²) 1.5
Conductor Diameter 1.52 mm [.06 in]
Insulation Thickness (mm) .2
Overall Outside Diameter 2.1 mm [.0826 in]
Wire Diameter 2.1 mm [.0826 in]

Other

Wire Source United Kingdom

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance
PDF